


# E60147



## Female cordset

ADOGK120MKR0010B12

Article no longer available - archive entry

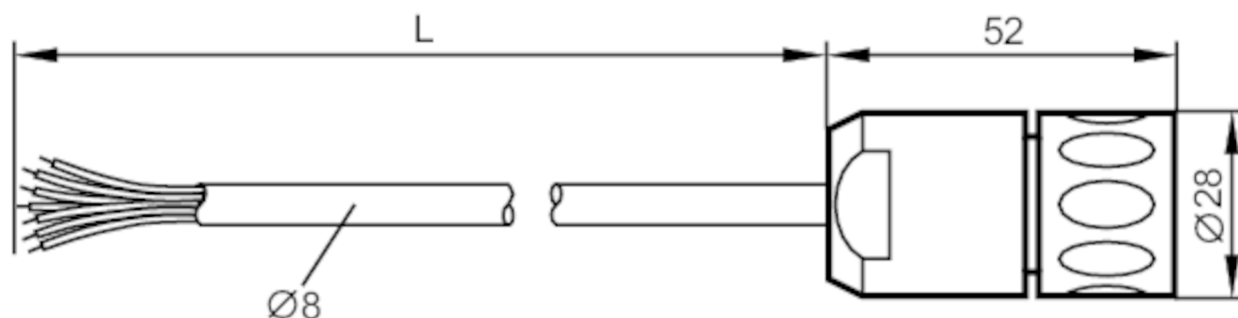

### Electrical data

Operating voltage	[V]	4.5...30 DC
-------------------	-----	-------------

### Operating conditions

Ambient temperature	[°C]	-25...80
---------------------	------	----------

Protection		IP 67
------------	--	-------

### Mechanical data

Weight	[g]	957.2
--------	-----	-------

Dimensions	[mm]	28 x 28 x 52
------------	------	--------------

Material		brass plastic coated; PA 6.6 black
----------	--	------------------------------------

Molded-body material		brass / PA 6.6, plastic coated
----------------------	--	--------------------------------

Material nut		brass, plastic coated / PA 6.6, plastic coated
--------------	--	--

### Remarks

Pack quantity		1 pcs.
---------------	--	--------

# E60147



## Female cordset

ADOGK120MKR0010B12


### Electrical connection

Cable: 10 m, PUR, Ø 8 mm; 8 x 0.14 mm<sup>2</sup> + 4 x 0.5 mm<sup>2</sup>

### Electrical connection - Socket

Connector: 1 x M23, straight; Moulded body: brass / PA 6.6, plastic coated; Locking: brass, plastic coated

Connector: 1 x M23, straight; Moulded body: brass / PA 6.6, plastic coated; Locking: PA 6.6, plastic coated

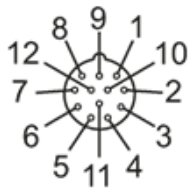

### Connection

1	PK
2	BU
3	RD
4	BK
5	BN
6	GN
7	VT
8	GY
9	n.c.
10	WH/GN
11	WH
12	BN/GN

	Core colors :
BK =	black
BN =	brown
BU =	blue
GN =	green
GY =	grey
PK =	pink
RD =	red
VT =	lilac
WH =	white