


E60174



Female wirable connectors

SDOGJ120MSLFBPG

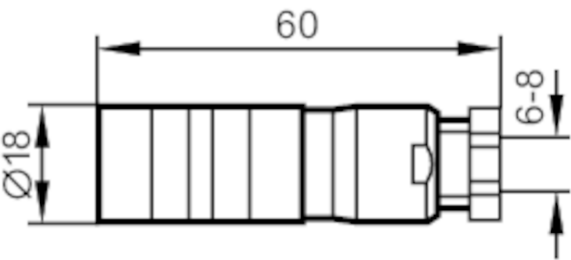

Electrical data		
Operating voltage	[V]	4.5...30 DC
Operating conditions		
Ambient temperature	[°C]	-40...85
Protection		IP 67
Mechanical data		
Weight	[g]	55.3
Dimensions	[mm]	18 x 18 x 60
Material		brass nickel-plated
Molded-body material		brass, nickel-plated
Material nut		brass, nickel-plated
Remarks		
Pack quantity		1 pcs.

# E60174



## Female wirable connectors


SDOGJ120MSLFKPG

### Electrical connection

soldering: ...0.25 mm<sup>2</sup>; Cable sheath: Ø 6...8 mm

### Electrical connection - Socket

Connector: 1 x M18, straight; Moulded body: brass, nickel-plated; Locking: brass, nickel-plated

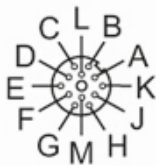

### Connection

