




AS-Interface flat cable insulation displacement connector

FC Splitter AS-i 0.6 m M12 UL

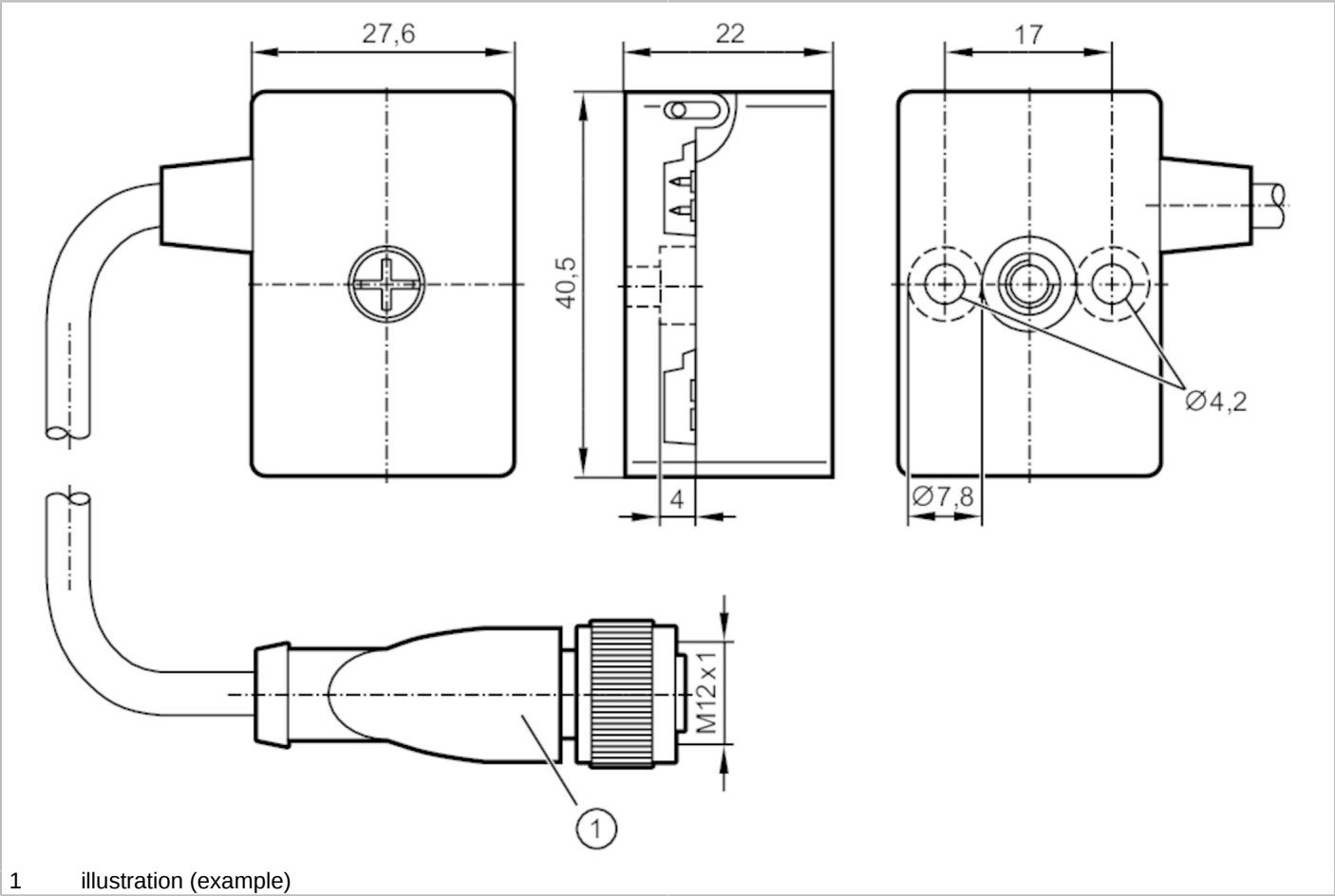

Application	
Application	distribution of the AS-i voltage to M12 socket
Electrical data	
Protection class	III
Max. current load per module/slot [A]	4
Outputs	
Electrical design	AS-i
Operating conditions	
Ambient temperature [°C]	-25...75
Protection	IP 67
Mechanical data	
Weight [g]	83.1
Material	housing: PBT / PC
Tightening torque [Nm]	1.65
Accessories	
Accessories (optional)	flat cable end seal:, E70413
	Heat-shrink cap:, E70113



AS-Interface flat cable insulation displacement
connector


FC Splitter AS-i 0.6 m M12 UL

Remarks	
Remarks	The flat cable must not end in the splitter. Use a flat cable seal or heat-shrink cap for sealing.
Pack quantity	1 pcs.


Electrical connection

Cable: 0.6 m, PUR, Ø 4.3 mm; 2 x 0.34 mm²

Connector: M12; coding: A; Moulded body: PUR

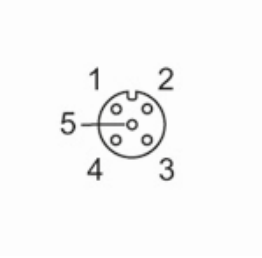

Connection

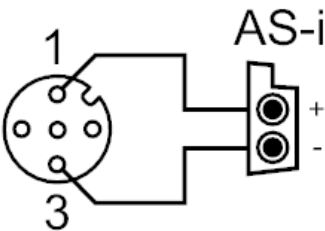

1	AS-i +
3	AS-i -