


E70588



AS-Interface power distributor

QUAD M12 AS-i/24V 4A

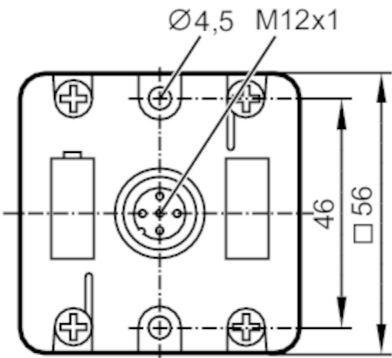

Application

Design	AS-i / 24 V
--------	-------------

Electrical data

Operating voltage	[V]	26.5...31.6 DC
Max. current load total	[A]	2
Additional voltage supply	[V]	24 DC

Operating conditions

Ambient temperature	[°C]	-25...75
Protection		IP 65

Mechanical data


Weight	[g]	95.5
Material		PA 6.6; Socket: stainless steel (1.4404 / 316L); screws: stainless steel (1.4404 / 316L); Nut: stainless steel (1.4404 / 316L); O-ring: NBR; Flat cable seal: NBR

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection

Connector: M12; coding: A

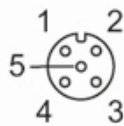

1	AS-i +
2	0V
3	AS-i -
4	+24V
5	functional earth