




AS-Interface flat cable insulation displacement connector

FC Splitter AS-i 2 m UL

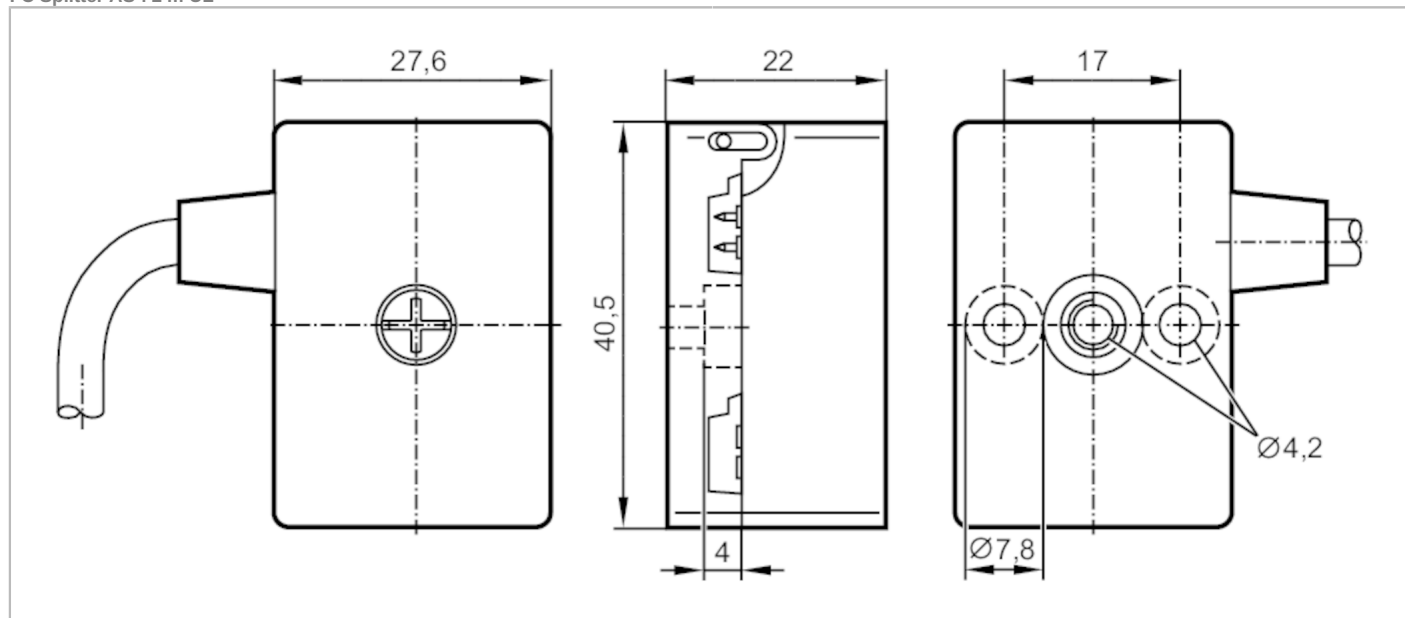

Electrical data

Protection class	III
Max. current load per module/slot [A]	4

Outputs

Electrical design	AS-i
-------------------	------

Operating conditions

Ambient temperature [°C]	-25...75
Protection	IP 67

Mechanical data

Weight [g]	108.1
Material	housing: PBT / PC; screw: stainless steel (1.4305 / 303)
Tightening torque [Nm]	< 1.65

Accessories

Accessories (optional)	flat cable end seal:, E70413
	Heat-shrink cap:, E70113

Remarks

Remarks	The flat cable should not end in the splitter. Use a flat cable seal or heat-shrink cap for sealing.
Pack quantity	1 pcs.

E70598




AS-Interface flat cable insulation displacement
connector

FC Splitter AS-i 2 m UL

Electrical connection

Cable: 2 m, Ø 4.3 mm; 2 x 0.5 mm²

Connection

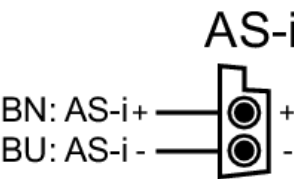

brown	AS-i +
blue	AS-i -