


# E70600



## AS-Interface power distributor

QUAD AS-i Splitter Box 8A

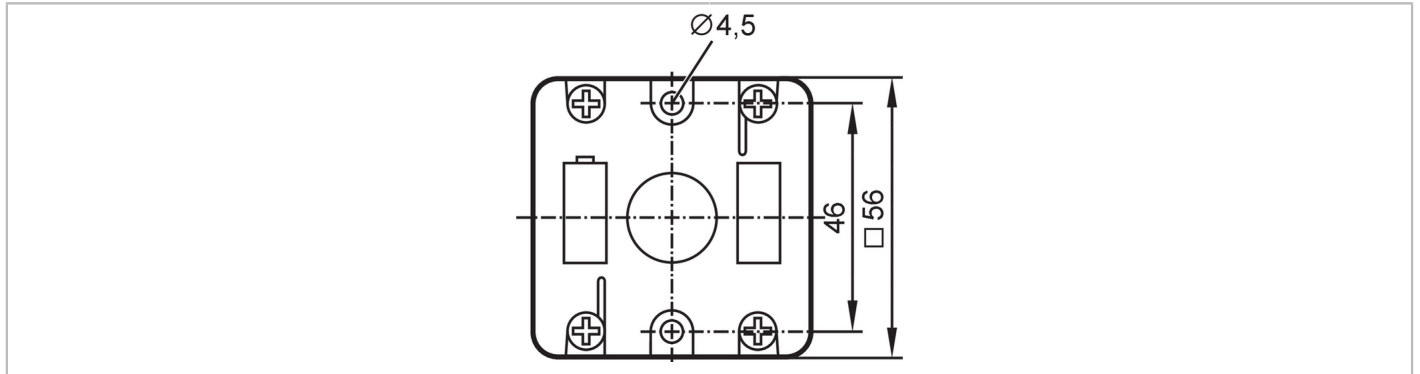

Application	
Design	AS-i / 24 V
Electrical data	
Operating voltage [V]	26.5...31.6 DC
Max. current load total [A]	8
Additional voltage supply [V]	24 DC
Operating conditions	
Ambient temperature [°C]	-25...75
Protection	IP 65
Mechanical data	
Weight [g]	89.5
Material	PA 6.6; screws: stainless steel (1.4404 / 316L); Nuts: stainless steel (1.4404 / 316L); Flat cable seal: NBR
Remarks	
Pack quantity	1 pcs.