


E70002



Male cordsets

ASTGH030MSS0005B03

Article no longer available - archive entry

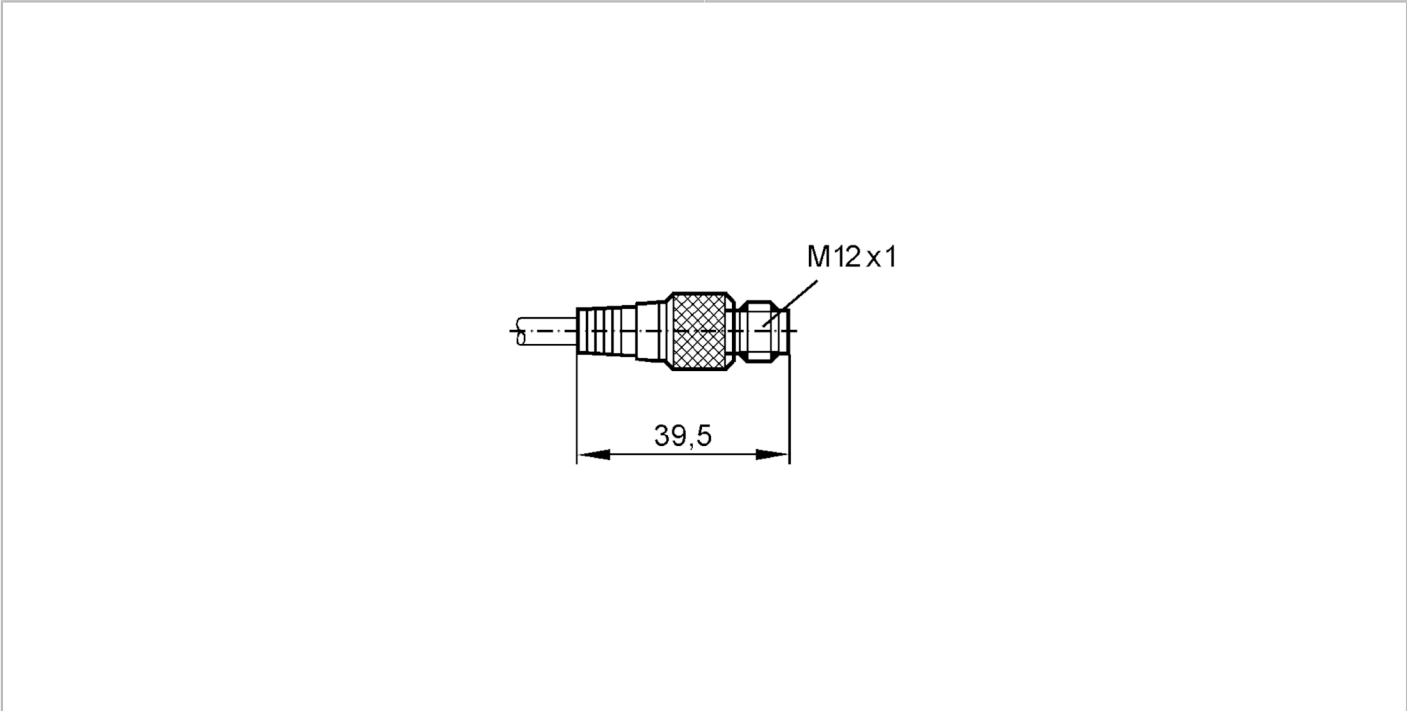


Electrical data		
Operating voltage	[V]	10...30 DC
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67
Mechanical data		
Material		TPU (urethane)
Molded-body material		TPU (urethane)
Material nut		brass, nickel-plated
Remarks		
Pack quantity		1 pcs.

Electrical connection

Cable: 5 m, PUR; 3 x 0.25 mm²

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated

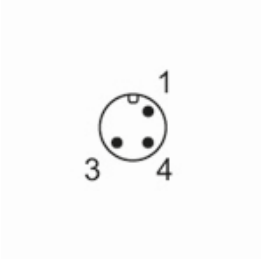


E70002



Male cordsets

ASTGH030MSS0005B03

Connection

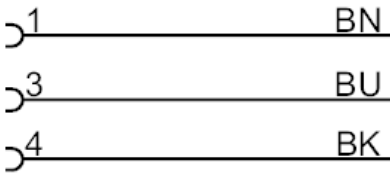

	Core colors :
BK =	black
BN =	brown
BU =	blue