


E70005



Connection cable


VSTA030MSS0002A02VDAB031--S

Article no longer available - archive entry

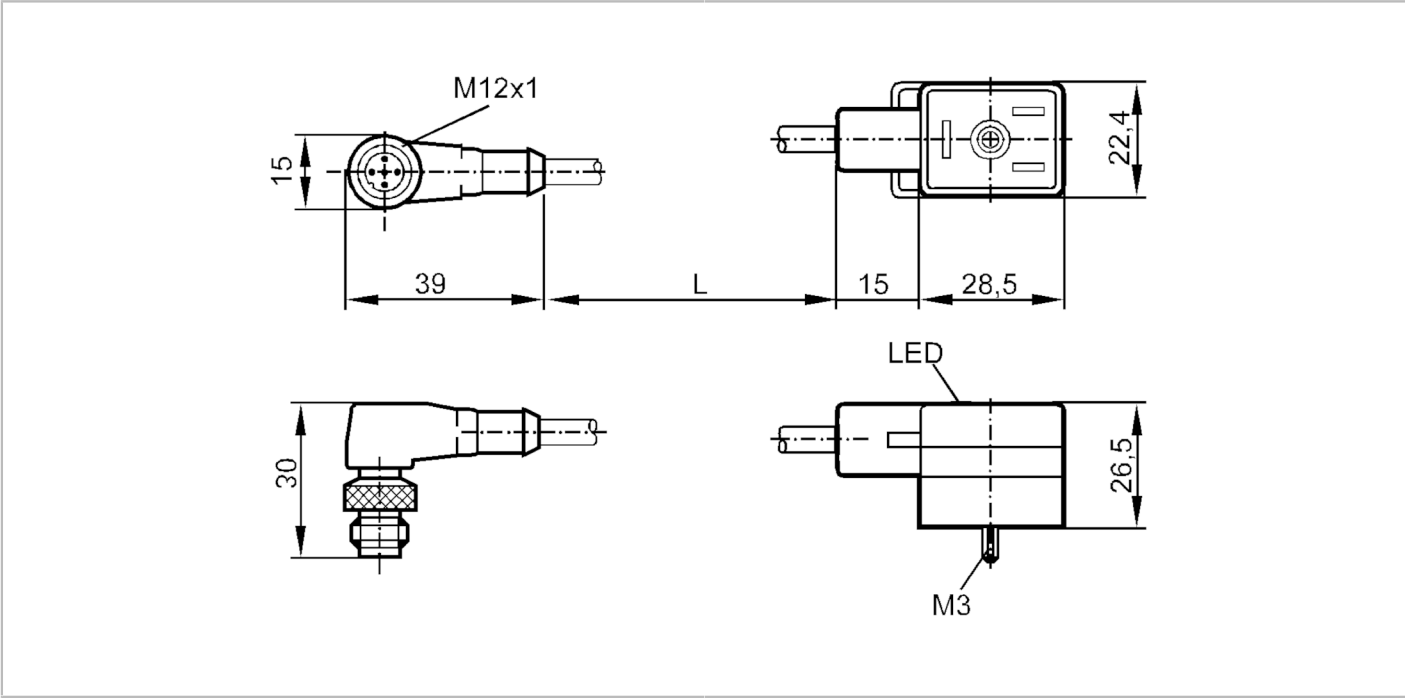

Electrical data		
Operating voltage	[V]	10...30 DC
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67
Mechanical data		
Dimensions	[mm]	15 x 30 x 39
Material		PUR
Molded-body material		PUR
Material nut		brass, nickel-plated
Accessories		
Items supplied		screw panel for labelling
Remarks		
Pack quantity		1 pcs.
Electrical connection - plug		

Connector: 1 x M12, angled; coding: A; Moulded body: PUR; Locking: brass, nickel-plated

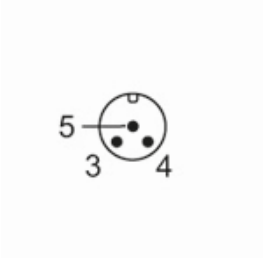

E70005




Connection cable

VSTAH030MSS0002A02VDAB031--S

Electrical connection

Cable: 2 m, PUR / PVC; 2 x

Connection

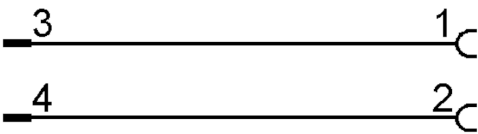

Electrical connection - Socket

Connector: 1 x valve type B DIN, angled; Moulded body: PUR; Locking: brass, nickel-plated

