


E70006



Connection cable


VVDAB031--S0015A03STAH030MSS

Article no longer available - archive entry

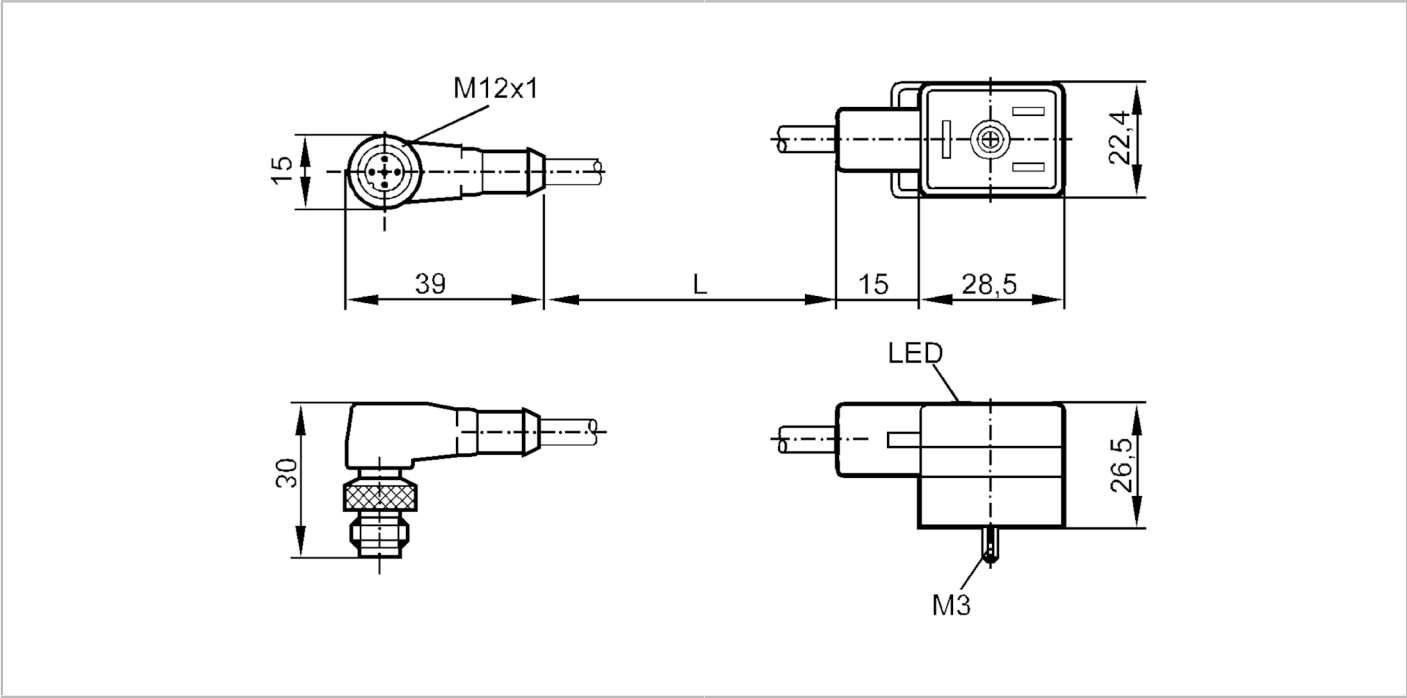

Electrical data		
Operating voltage	[V]	10...30 DC
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67
Mechanical data		
Dimensions	[mm]	15 x 30 x 39
Material		PUR
Molded-body material		PUR
Material nut		brass, nickel-plated
Accessories		
Items supplied		screw
		panel for labelling
Remarks		
Pack quantity		1 pcs.
Electrical connection - plug		

Connector: 1 x M12, angled; coding: A; Moulded body: PUR; Locking: brass, nickel-plated

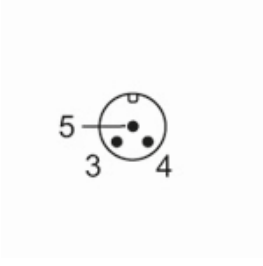

E70006




Connection cable

VVDAB031--S0015A03STAH030MSS

Electrical connection

Cable: 15 m, PUR / PVC; 2 x

Connection

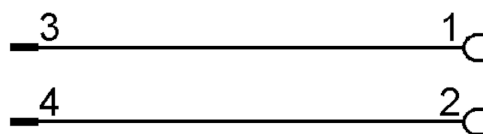

Electrical connection - Socket

Connector: 1 x valve type B DIN, angled; Moulded body: PUR; Locking: brass, nickel-plated

