


E70026



Connection cable

VDOAF030MSS01,5A03STGH030MSS

Article no longer available - archive entry

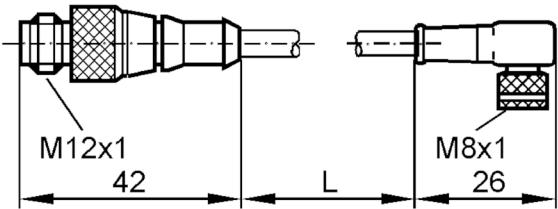

Electrical data		
Operating voltage	[V]	10...30 DC
Protection class		III


Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67

Mechanical data		
Material		TPU (urethane)
Molded-body material		TPU (urethane)
Material nut		brass, nickel-plated

Remarks		
Pack quantity		1 pcs.

Electrical connection - plug

 Connector: 1 x M12, straight; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated



E70026




Connection cable

VDOAF030MSS01,5A03STGH030MSS

Electrical connection

Cable: 1.5 m, PUR / PVC; 3 x 0.34 mm²

Connection

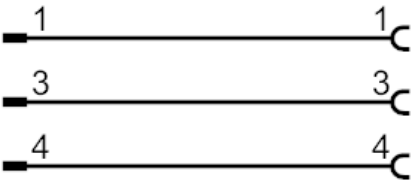

Electrical connection - Socket

Connector: 1 x M8, angled; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated

