


E70053



Connection cable

VDOAH040MSS00,6A04STAH040MSS

Article no longer available - archive entry

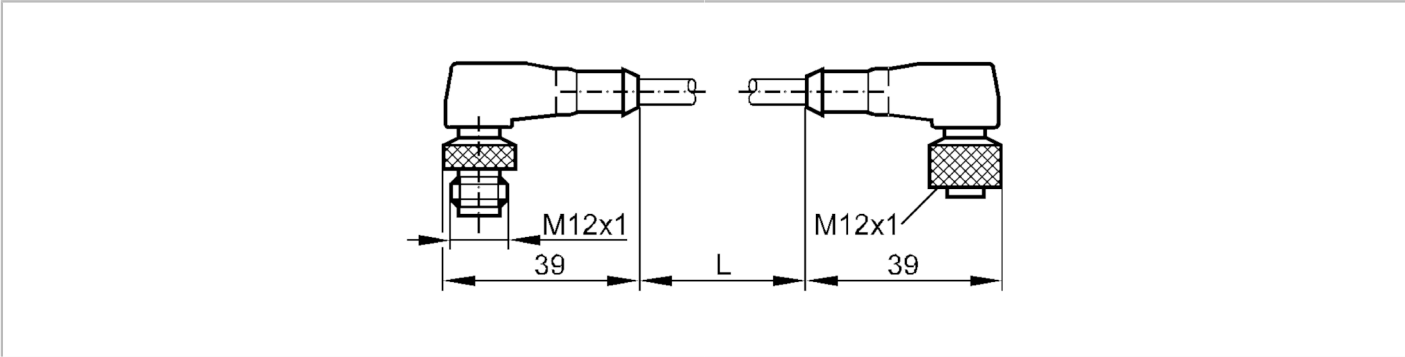

Electrical data

Operating voltage	[V]	10...30 DC
-------------------	-----	------------

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 67

Mechanical data


Material	TPU (urethane)
Molded-body material	TPU (urethane)
Material nut	brass, nickel-plated

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection - plug

Connector: 1 x M12, angled; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated

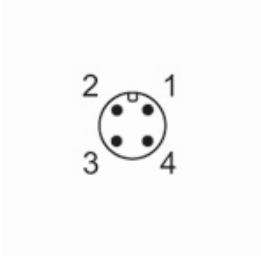

E70053




Connection cable

VDOAH040MSS00,6A04STAH040MSS

Electrical connection

Cable: 0.6 m, PUR / PVC, orange, Ø 5 mm; 4 x 0.25 mm²

Connection

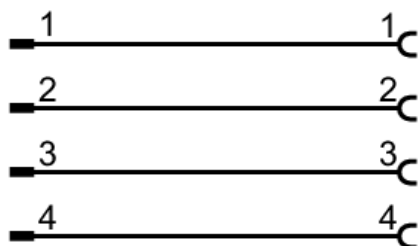

Electrical connection - Socket

Connector: 1 x M12, angled; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated

