


Y connection cable

YDOAH032MSS0001H03STGH040MSS

Article no longer available - archive entry

Alternative articles: EVC437

When selecting an alternative article and accessories please note that technical data may differ!

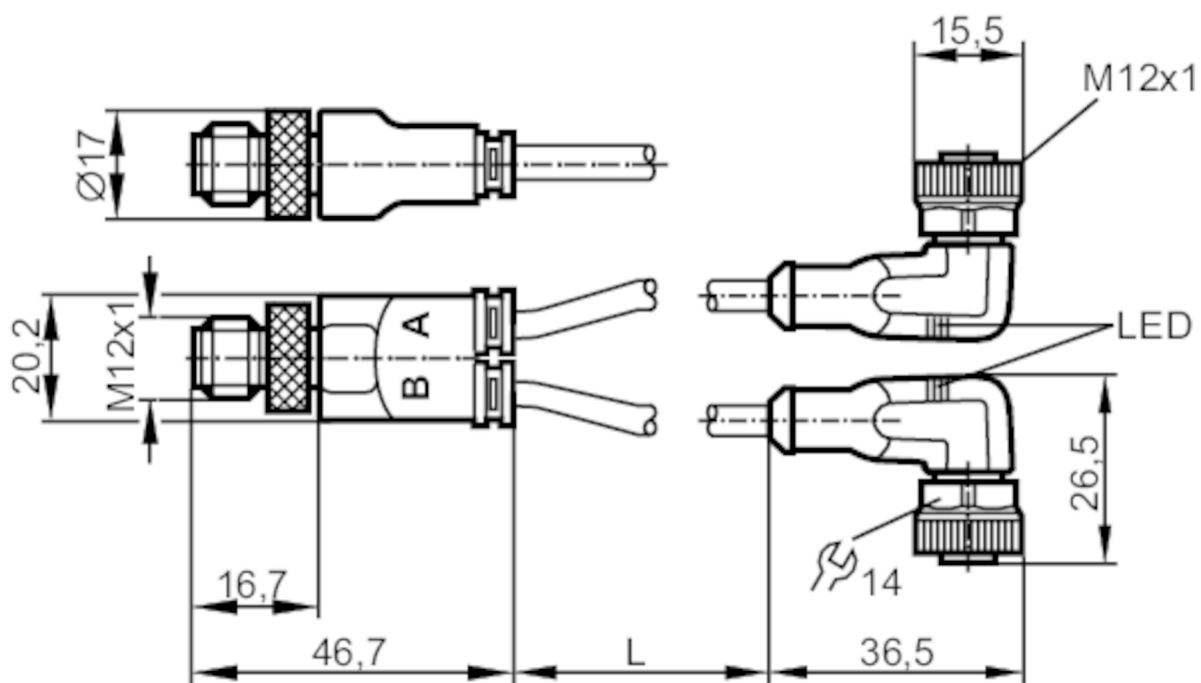

Electrical data

Operating voltage	[V]	10...30 DC
Max. current load total	[A]	4

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 67

Mechanical data

Weight	[g]	0.108
Molded-body material		TPU (urethane)
Material nut		brass, nickel-plated
Sealing material		FKM
Number of ports splitter box		2

Displays / operating elements

Display	Switching status	1 x LED, yellow
	Power	1 x LED, green

Remarks

Pack quantity	1 pcs.
---------------	--------

E70063



Y connection cable

YDOAH032MSS0001H03STGH040MSS

Electrical connection


Cable: 1 m, PUR, black, Ø 4.9 mm; 3 x 0.34 mm² (42 x Ø 0.1 mm)

Electrical connection - plug C

Connector: 1 x M12, straight; coding: A; Moulded body: TPU (urethane), black; Locking: brass, nickel-plated; Tightening torque: 0.6...1.5 Nm



Connection

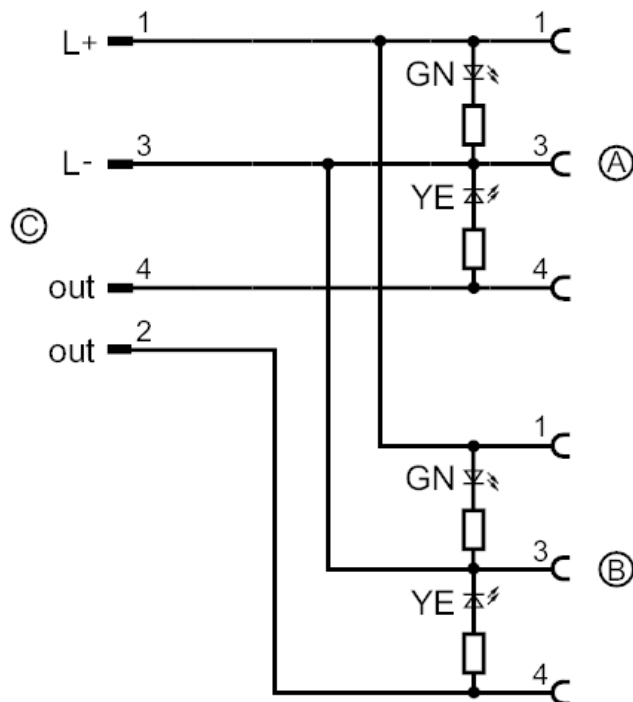

Electrical connection - Socket A

Connector: 1 x M12, angled; coding: A; Moulded body: TPU (urethane), black transparent; Locking: brass, nickel-plated; sealing: FKM; Tightening torque: 0.6...1.5 Nm



E70063



Y connection cable

YDOAH032MSS0001H03STGH040MSS

Electrical connection - Socket B

Connector: 1 x M12, angled; coding: A; Moulded body: TPU (urethane), black transparent; Locking: brass, nickel-plated; sealing: FKM; Tightening torque: 0.6...1.5 Nm

