




Patchcords with valve plug

VVSAC041--S00,3A03STGH030MSS

Article no longer available - archive entry

Alternative articles: E11436
When selecting an alternative article and accessories please note that technical data may differ!

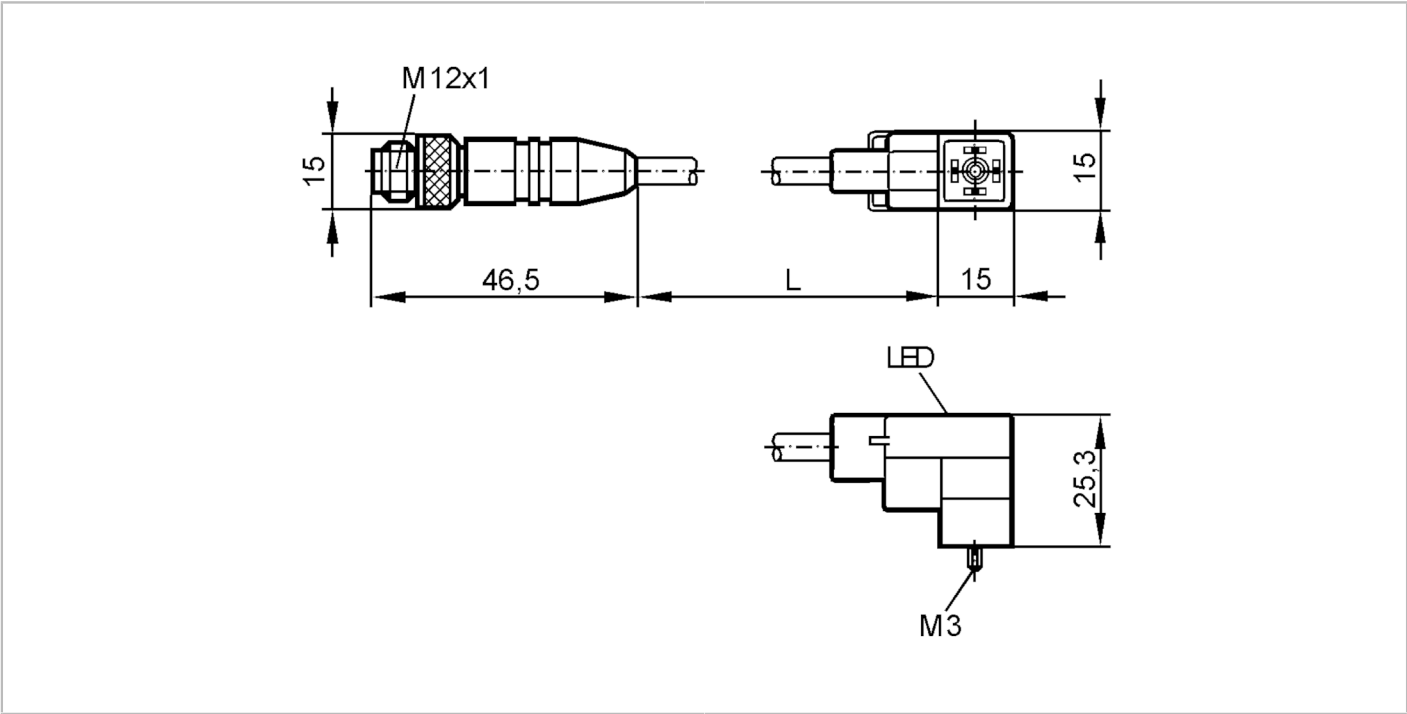

Electrical data		
Operating voltage	[V]	< 24 AC/DC
Overtoltage protection		yes; (VDR)
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67
Mechanical data		
Material		TPU (urethane)
Molded-body material		TPU (urethane)
Material nut		brass, nickel-plated
Displays / operating elements		
Display	Switching status	1 x LED, yellow
Accessories		
Items supplied		screw
		panel for labelling
Remarks		
Pack quantity		1 pcs.

E70081



Patchcords with valve plug

VVSAC041--S00,3A03STGH030MSS

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated



Electrical connection

Cable: 0.3 m, PUR / PVC; 3 x 0.5 mm²

Connection



Electrical connection - Socket

Connector: 1 x valve type C industrial standard, angled; Moulded body: TPU (urethane); Locking: brass, nickel-plated

