

# E70090




## Patchcords with valve plug

VVSAB031--S01,5A03STGH030MSS

Article no longer available - archive entry

Alternative articles: E11431

When selecting an alternative article and accessories please note that technical data may differ!

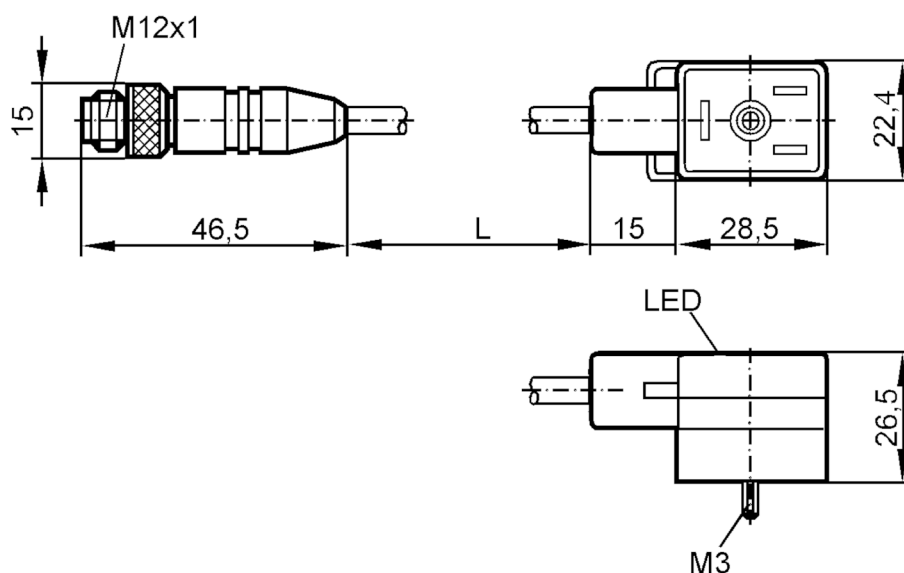

### Electrical data

|                        |     |            |
|------------------------|-----|------------|
| Operating voltage      | [V] | < 24 AC/DC |
| Overtoltage protection |     | yes; (VDR) |

### Operating conditions

|                     |      |          |
|---------------------|------|----------|
| Ambient temperature | [°C] | -25...90 |
| Protection          |      | IP 67    |

### Mechanical data

|                      |                      |
|----------------------|----------------------|
| Material             | TPU (urethane)       |
| Molded-body material | TPU (urethane)       |
| Material nut         | brass, nickel-plated |

### Displays / operating elements

|         |                  |                 |
|---------|------------------|-----------------|
| Display | Switching status | 1 x LED, yellow |
|---------|------------------|-----------------|

### Accessories

|                |                     |
|----------------|---------------------|
| Items supplied | screw               |
|                | panel for labelling |

### Remarks

|               |        |
|---------------|--------|
| Pack quantity | 1 pcs. |
|---------------|--------|

# E70090




## Patchcords with valve plug

VVSAB031--S01,5A03STGH030MSS

### Electrical connection - plug

 
Connector: 1 x M12, straight; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated



### Electrical connection

Cable: 1.5 m, PUR / PVC; 3 x 0.5 mm<sup>2</sup>

### Connection

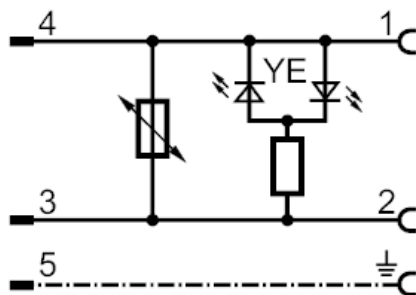

### Electrical connection - Socket

Connector: 1 x valve type B industrial standard, angled; Moulded body: TPU (urethane); Locking: brass, nickel-plated

