

E70103




Patchcords with valve plug

VVDAB031--S00,3A03STGH030MSS

Article no longer available - archive entry

Alternative articles: E11421

When selecting an alternative article and accessories please note that technical data may differ!

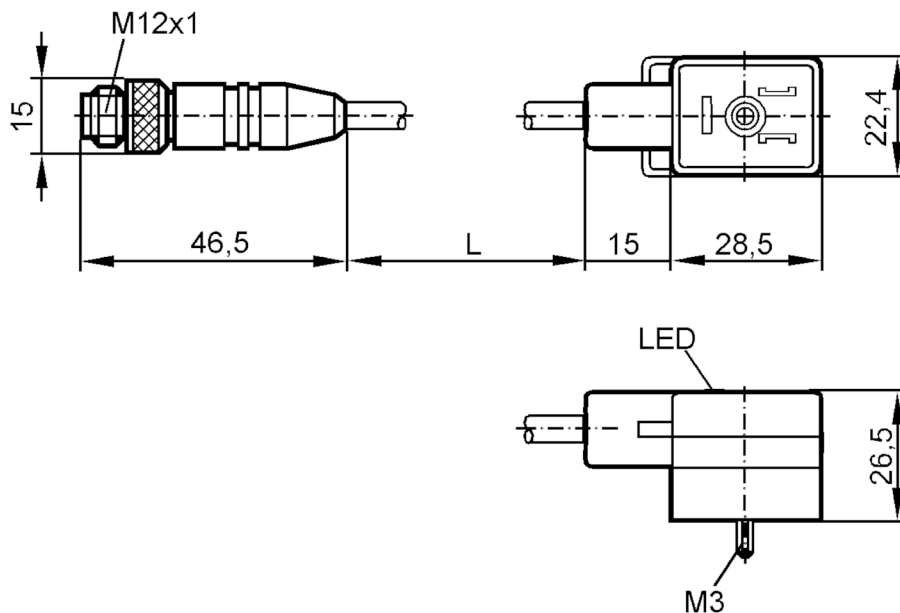

Electrical data

Operating voltage	[V]	< 24 AC/DC
Overtoltage protection		yes; (VDR)

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 67

Mechanical data

Dimensions	[mm]	15 x 15 x 46.5
Material		TPU (urethane)
Molded-body material		TPU (urethane)
Material nut		brass, nickel-plated

Displays / operating elements

Display	Switching status	1 x LED, yellow
---------	------------------	-----------------

Accessories

Items supplied	screw
	panel for labelling

Remarks

Pack quantity	1 pcs.
---------------	--------

E70103




Patchcords with valve plug

VVDAB031--S00,3A03STGH030MSS

Electrical connection - plug

 
Connector: 1 x M12, straight; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated



Electrical connection

Cable: 0.3 m, PUR / PVC; 3 x 0.5 mm²

Connection

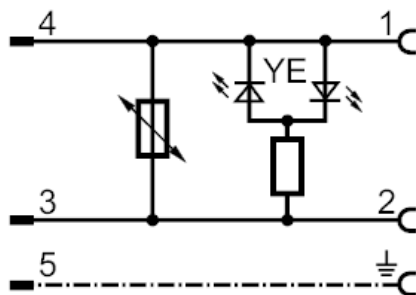

Electrical connection - Socket

Connector: 1 x valve type B DIN, angled; Moulded body: TPU (urethane); Locking: brass, nickel-plated

