


E70115



Connection cable

VDOGH040MSS0001A03STGH030MSS

Article no longer available - archive entry

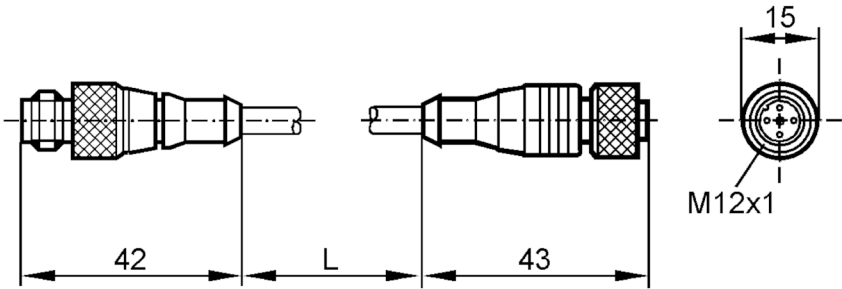

Electrical data		
Operating voltage	[V]	10...30 DC
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67
Mechanical data		
Dimensions	[mm]	15 x 15 x 42
Material		TPU (urethane)
Molded-body material		TPU (urethane)
Material nut		brass, nickel-plated
Remarks		
Pack quantity		1 pcs.
Electrical connection - plug		

Connector: 1 x M12, straight; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated



E70115




Connection cable

VDOGH040MSS0001A03STGH030MSS

Electrical connection

Cable: 1 m, PUR / PVC, orange, Ø 5 mm; 3 x 0.34 mm²

Connection

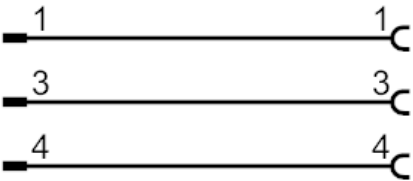

Electrical connection - Socket

Connector: 1 x M12, straight; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated

