


# E70121



## Male cordsets

ASTGH040MS-0005A03

Article no longer available - archive entry

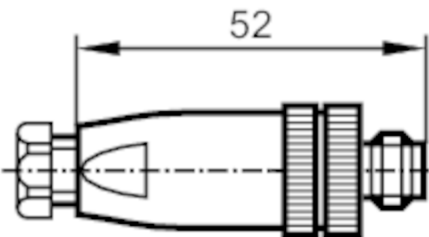

| Electrical data                    |      |                      |
|------------------------------------|------|----------------------|
| Operating voltage                  | [M]  | 10...36 DC           |
| Operating conditions               |      |                      |
| Ambient temperature                | [°C] | -25...90             |
| Protection                         |      | IP 67                |
| Mechanical data                    |      |                      |
| Dimensions                         | [mm] | 20 x 20 x 52         |
| Material                           |      | PA                   |
| Molded-body material               |      | PA                   |
| Material nut                       |      | brass, nickel-plated |
| Remarks                            |      |                      |
| Pack quantity                      |      | 1 pcs.               |
| Electrical connection              |      |                      |
| Cable: 5 m, PUR / PVC; 3 x 0.5 mm² |      |                      |
| Electrical connection - plug       |      |                      |

Connector: 1 x M12, straight; coding: A; Moulded body: PA; Locking: brass, nickel-plated



# E70121



## Male cordsets

ASTGH040MS-0005A03

### Connection

