

E70133




Female wirable connectors

SDOKL070PLSFKPG

Article no longer available - archive entry

Alternative articles: E70142
When selecting an alternative article and accessories please note that technical data may differ!

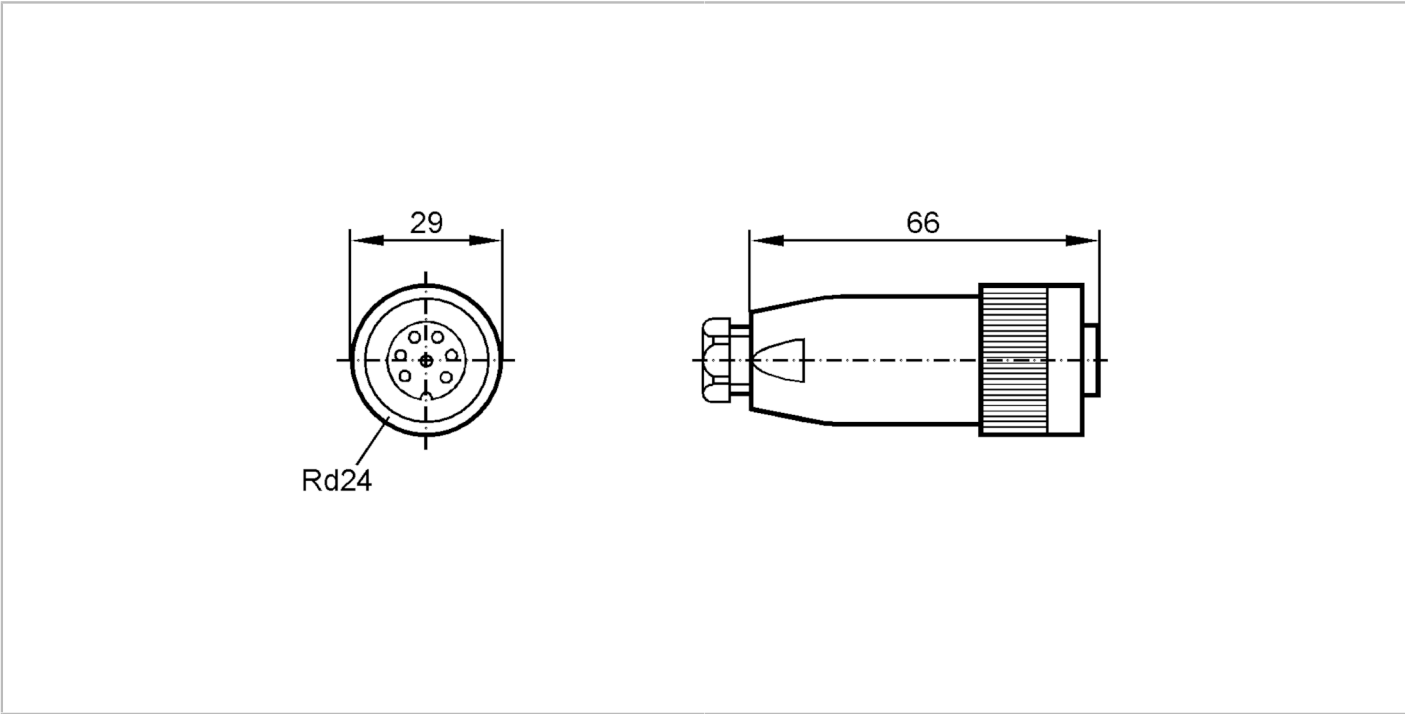

Electrical data		
Operating voltage	[V]	< 250 AC / < 300 DC
Operating conditions		
Ambient temperature	[°C]	-40...100
Protection		IP 67
Mechanical data		
Dimensions	[mm]	29 x 29 x 66
Material		PBT
Molded-body material		PBT
Material nut		PBT
Remarks		
Pack quantity		1 pcs.

E70133



Female wirable connectors

 
SDOKL070PLSFKPG

Electrical connection

terminals: ...2.5 mm²; Cable sheath: Ø 6...9.5 mm

Electrical connection - Socket

Connector: 1 x Rd24, straight; coding: A; Moulded body: PBT; Locking: PBT



Connection

