


# E70145



## Patchcords with valve plug

VVDAB031--S00,6A03STAH030VAS

Article no longer available - archive entry

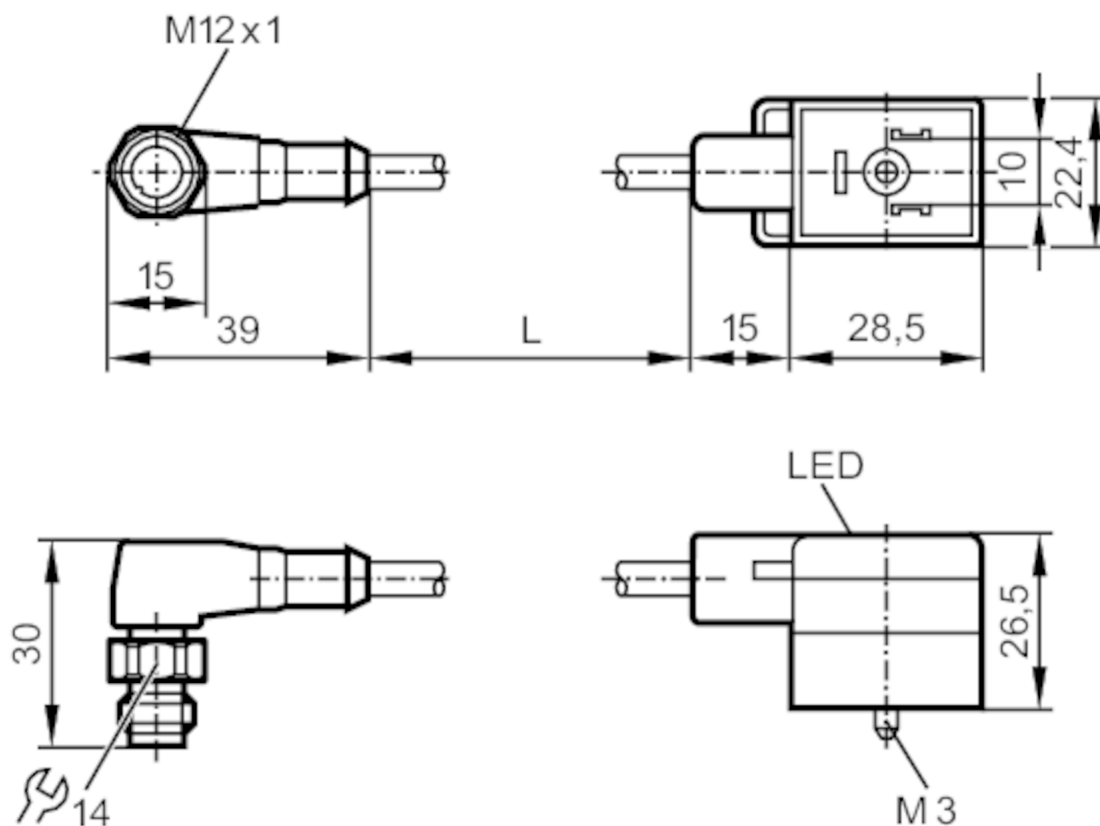

### Application

System Halogen-free

### Electrical data

Operating voltage [V] < 24 AC/DC

### Operating conditions

Ambient temperature [°C] -25...90

Protection IP 67

### Mechanical data

Dimensions [mm] 30 x 15 x 39

Material PUR

Molded-body material PUR

Material nut stainless steel (1.4404 / 316L)

### Displays / operating elements

Display Switching status 1 x LED, yellow

### Accessories

Items supplied screw  
panel for labelling

# E70145



## Patchcords with valve plug


VVDAB031--S00,6A03STAH030VAS

### Remarks

|               |        |
|---------------|--------|
| Pack quantity | 1 pcs. |
|---------------|--------|

### Electrical connection - plug


Connector: 1 x M12, angled; coding: A; Moulded body: PUR; Locking: stainless steel (1.4404 / 316L)

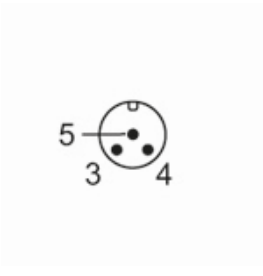

### Electrical connection

Cable: 0.6 m, PUR, Halogen-free, black, Ø 5.5 mm; 3 x 0.5 mm² (16 x Ø 0.2 mm )

### Connection

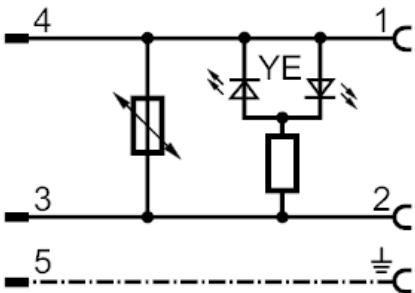

### Electrical connection - Socket

Connector: 1 x valve type B DIN, angled; Moulded body: PUR; Locking: stainless steel (1.4404 / 316L)

