

E70165




Female cordset

ADOGB030PLS0002E03

Article no longer available - archive entry

Alternative articles: E20428
When selecting an alternative article and accessories please note that technical data may differ!

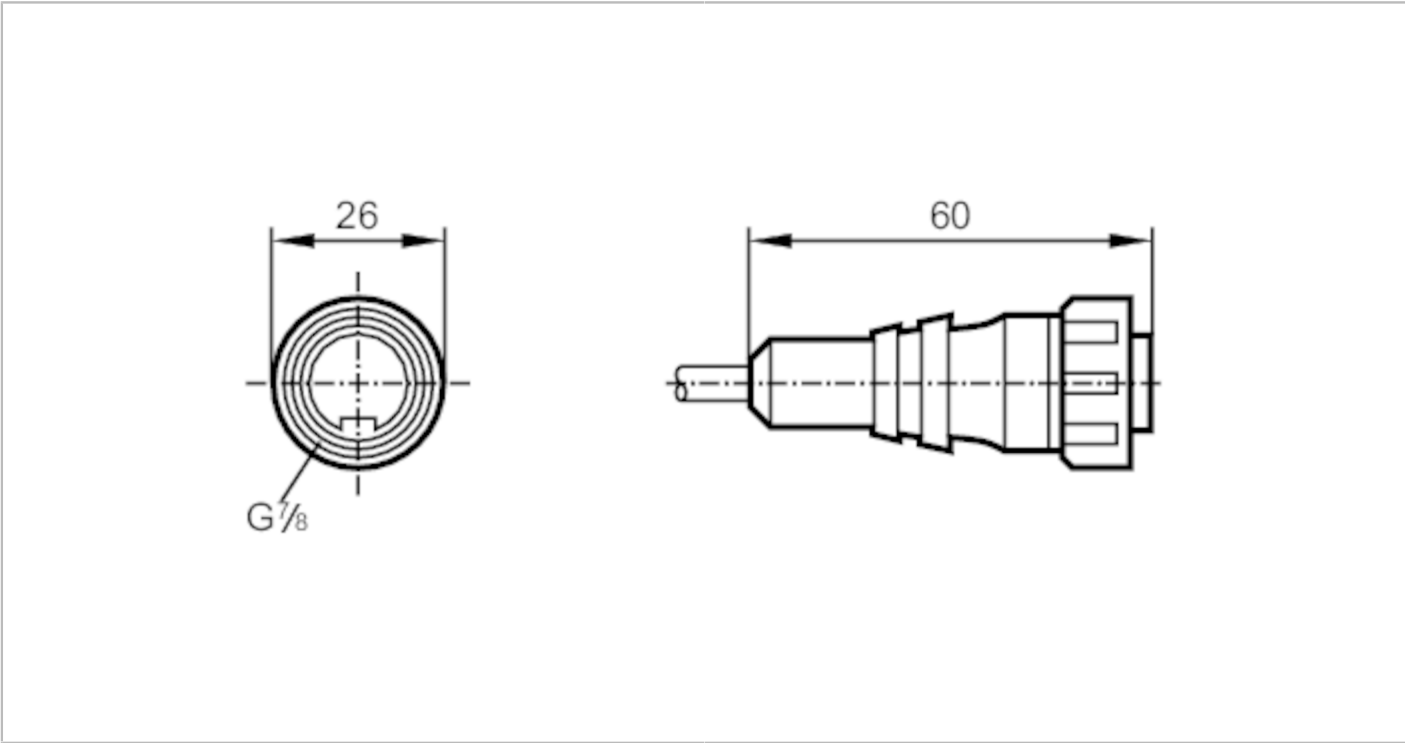

Electrical data		
Operating voltage	[V]	< 250 AC
Operating conditions		
Ambient temperature	[°C]	-40...90
Protection		IP 68
Mechanical data		
Dimensions	[mm]	26 x 26 x 60
Material		TPU (urethane)
Molded-body material		TPU (urethane)
Material nut		PA
Remarks		
Pack quantity		1 pcs.

E70165



Female cordset

ADOGB030PLS0002E03

Electrical connection


Cable: 2 m, PVC, orange, Ø 7.2 mm; 3 x 0.75 mm² (22 x Ø 0.2 mm)

Electrical connection - Socket

Connector: 1 x 7/8", straight; coding: A; Moulded body: TPU (urethane); Locking: PA



Connection

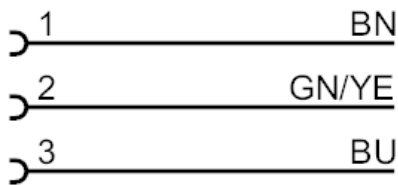

BN =	Core colors :
BU =	brown
GN/YE =	blue
	green/yellow