


E70172



Male cordsets

ASTGB040PLS0005E04

Article no longer available - archive entry

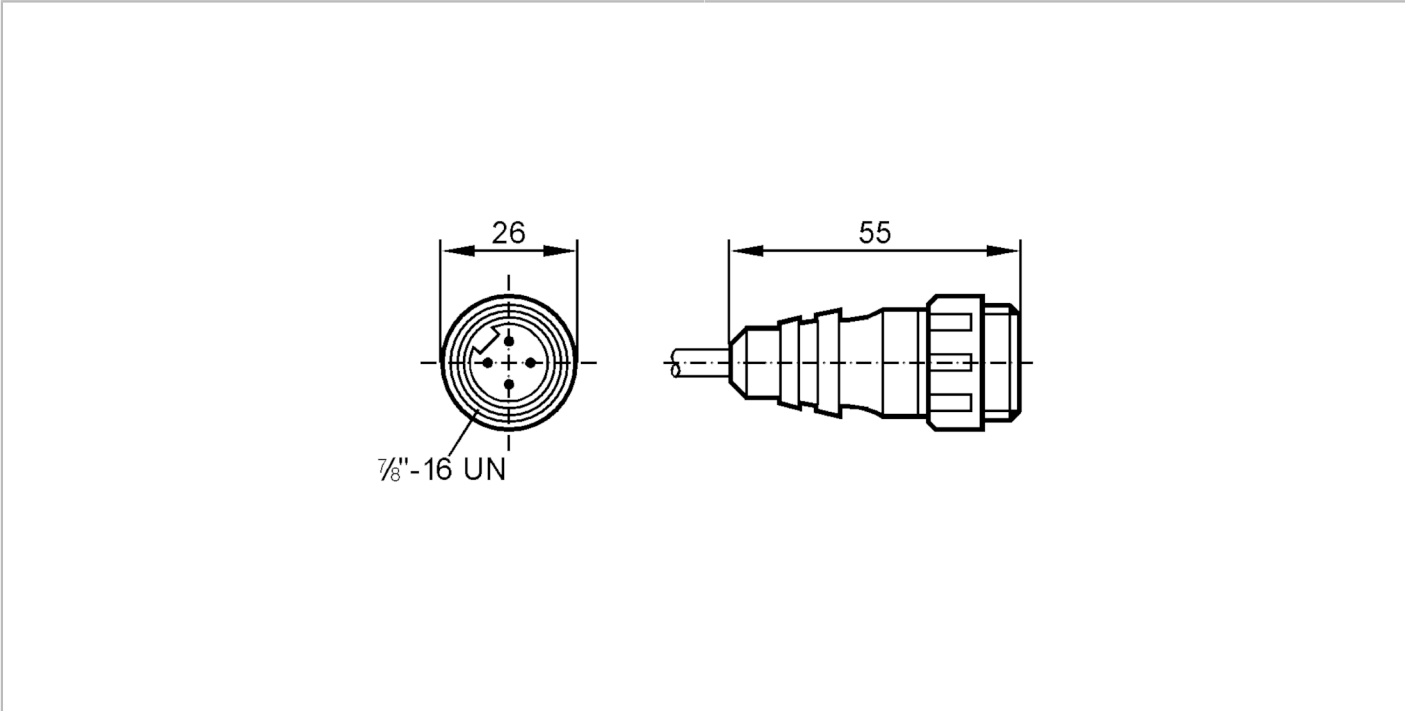

Electrical data

Operating voltage	[V]	< 250 AC / 10...55 DC
-------------------	-----	-----------------------

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 67

Mechanical data

Dimensions	[mm]	26 x 26 x 55
Material		TPU (urethane)
Molded-body material		TPU (urethane)
Material nut		PA

Remarks


Remarks	Pin 2 leading
Pack quantity	1 pcs.

Electrical connection

Cable: 5 m, PVC, orange, Ø 6.3 mm; 4 x 0.5 mm² (16 x Ø 0.2 mm)

Electrical connection - plug

Connector: 1 x 7/8", straight; coding: A; Moulded body: TPU (urethane); Locking: PA; Tightening torque: 0.5 Nm

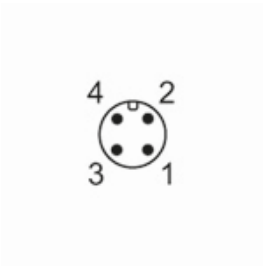


E70172



Male cordsets

ASTGB040PLS0005E04

Connection

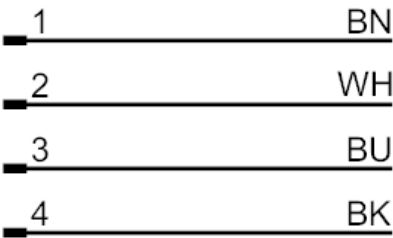

	Core colors :
BK =	black
BN =	brown
BU =	blue
WH =	white