

E70185




Connection cable

VDOGH040VAS0005E04STGH040VAS

Article no longer available - archive entry

Alternative articles: EVT044
When selecting an alternative article and accessories please note that technical data may differ!

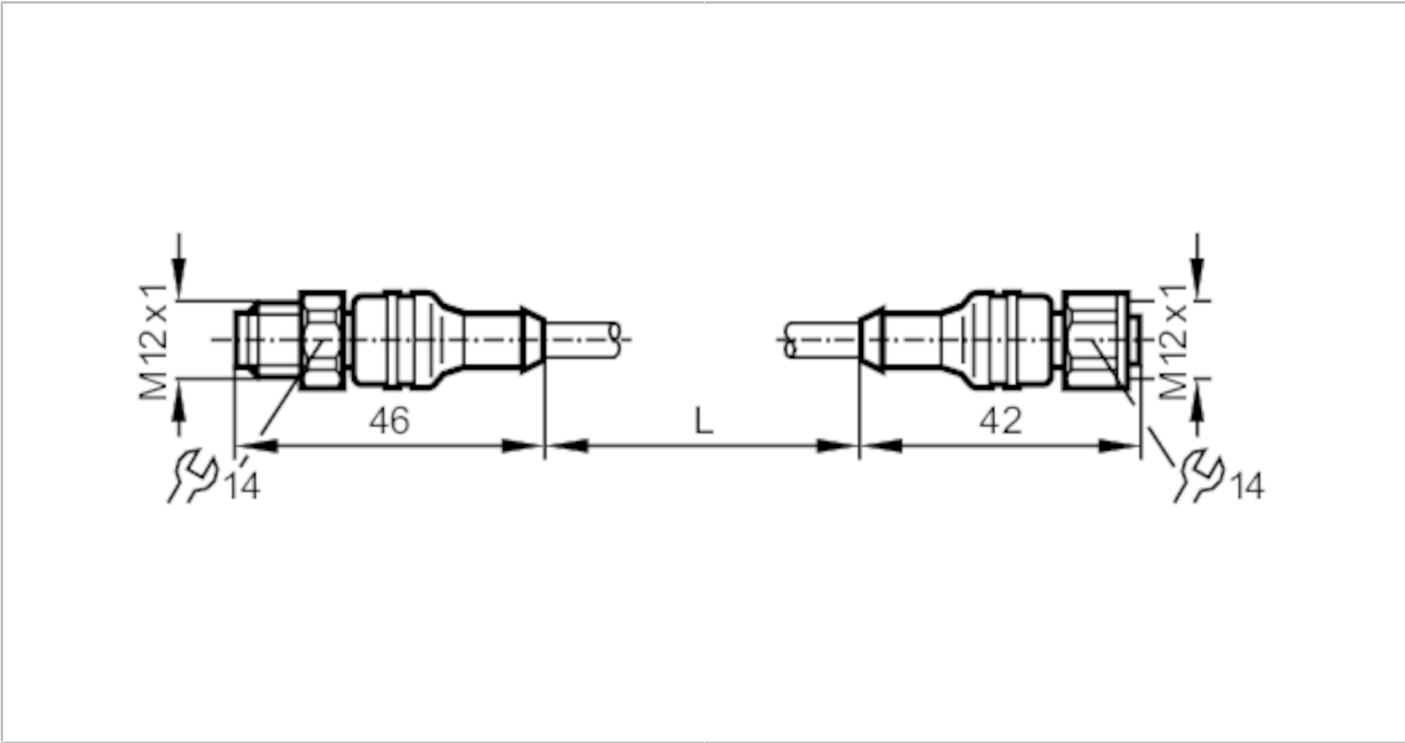

Application	
System	Free from silicone; gold-plated contacts
Free from silicone	yes
Electrical data	
Operating voltage [V]	< 250 AC / < 300 DC
Max. current load total [A]	4
Operating conditions	
Ambient temperature [°C]	-25...70
Protection	IP 67
Mechanical data	
Material	PVC
Molded-body material	PVC
Material nut	stainless steel (1.4404 / 316L)
Remarks	
Pack quantity	1 pcs.

E70185



Connection cable

VDOGH040VAS0005E04STGH040VAS

Electrical connection - plug


Connector: 1 x M12, straight; coding: A; Moulded body: PVC; Locking: stainless steel (1.4404 / 316L); Contacts: gold-plated



Electrical connection

Cable: 5 m, PVC, orange, Ø 5 mm; 4 x 0.25 mm² (32 x Ø 0.1 mm)

Connection

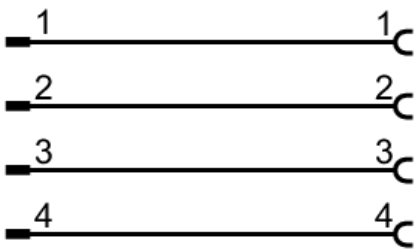

Electrical connection - Socket

Connector: 1 x M12, straight; coding: A; Moulded body: PVC; Locking: stainless steel (1.4404 / 316L); Contacts: gold-plated

