


E70203



Y-splitter with valve plug

YVDAA042--S0001H03STGH050MSS

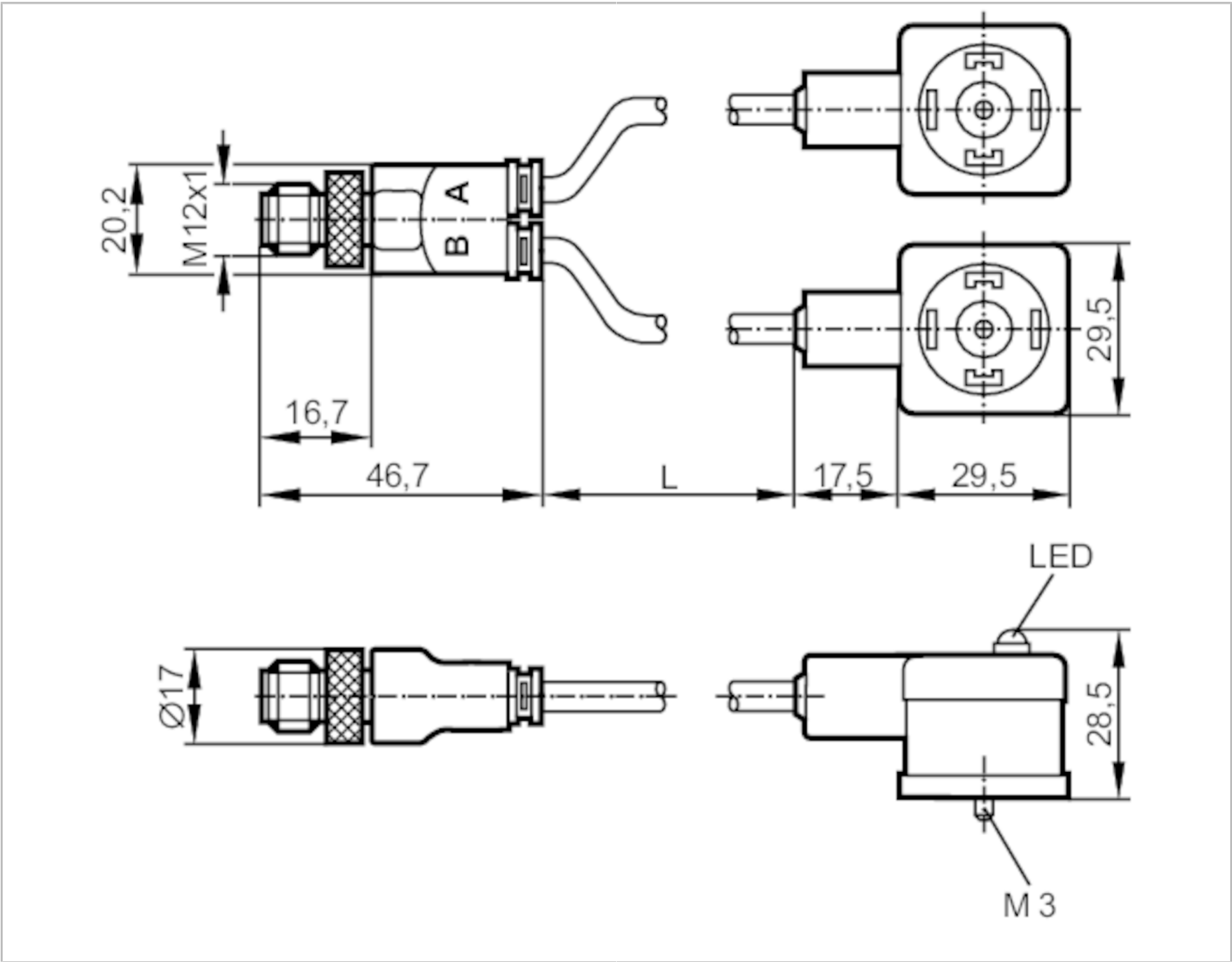

Application

System	Halogen-free
--------	--------------

Electrical data

Operating voltage [V]	10...30 DC
Overvoltage protection	yes; (VDR)

Operating conditions

Ambient temperature [°C]	-25...90
Protection	IP 65

Mechanical data

Weight [g]	183.5
Material	TPU (urethane)
Molded-body material	TPU (urethane)
Material nut	brass, nickel-plated

Displays / operating elements

Display	Switching status	2 x LED, yellow
---------	------------------	-----------------

E70203



Y-splitter with valve plug

YVDAA042--S0001H03STGH050MSS

Accessories


Items supplied	screw
	panel for labelling

Remarks


Pack quantity	1 pcs.
---------------	--------

Electrical connection - plug

Connection

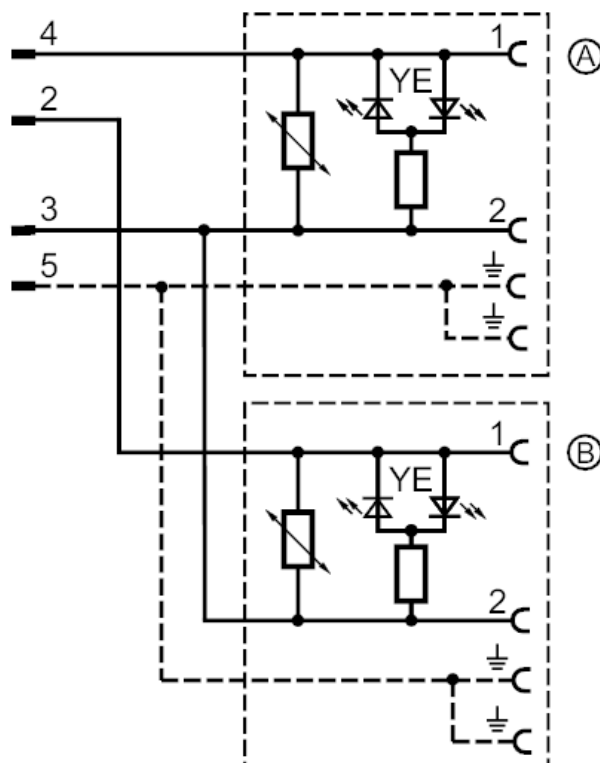

Connector: 1 x M12, straight; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated

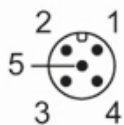

E70203



Y-splitter with valve plug

YVDAA042--S0001H03STGH050MSS

Electrical connection

Cable: 1 m, PUR, Halogen-free, black, Ø 4.8 mm; 3 x 0.5 mm² (16 x Ø 0.2 mm)

Electrical connection - Socket

Connector: 2 x valve type A DIN, angled; Moulded body: TPU (urethane); Locking: brass, nickel-plated

