

E70214




Patchcords with valve plug

VVDAA041--S0002B03STGH030MSS

Article no longer available - archive entry

Alternative articles: E11419

When selecting an alternative article and accessories please note that technical data may differ!

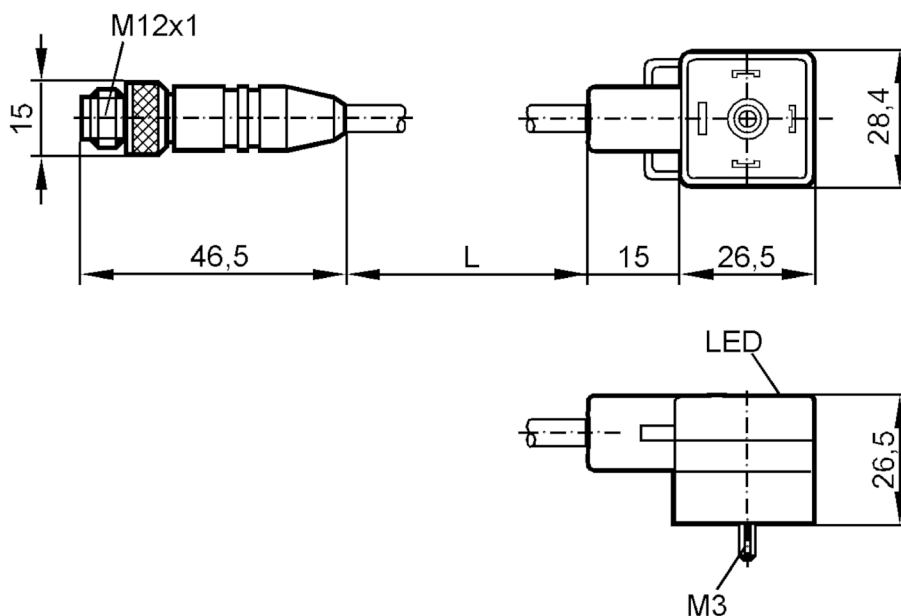

Electrical data

Operating voltage	[V]	< 24 AC/DC
Overtoltage protection		yes; (VDR)

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 67

Mechanical data

Dimensions	[mm]	15 x 15 x 46.5
Material		TPU (urethane)
Molded-body material		TPU (urethane)
Material nut		brass, nickel-plated

Accessories

Items supplied		screw
		panel for labelling

Remarks

Pack quantity		1 pcs.
---------------	--	--------

E70214



Patchcords with valve plug

VVDAA041--S0002B03STGH030MSS

Electrical connection - plug


Connector: 1 x M12, straight; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated



Electrical connection

Cable: 2 m, PUR; 3 x 0.5 mm²

Connection

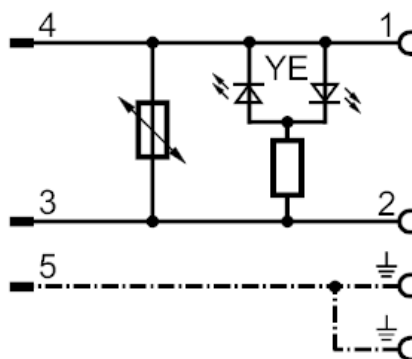

Electrical connection - Socket

Connector: 1 x valve type A DIN, angled; Moulded body: TPU (urethane); Locking: brass, nickel-plated

