


E70215



Patchcords with valve plug

VVDAA042--S0005B05STGH050MSS

Article no longer available - archive entry

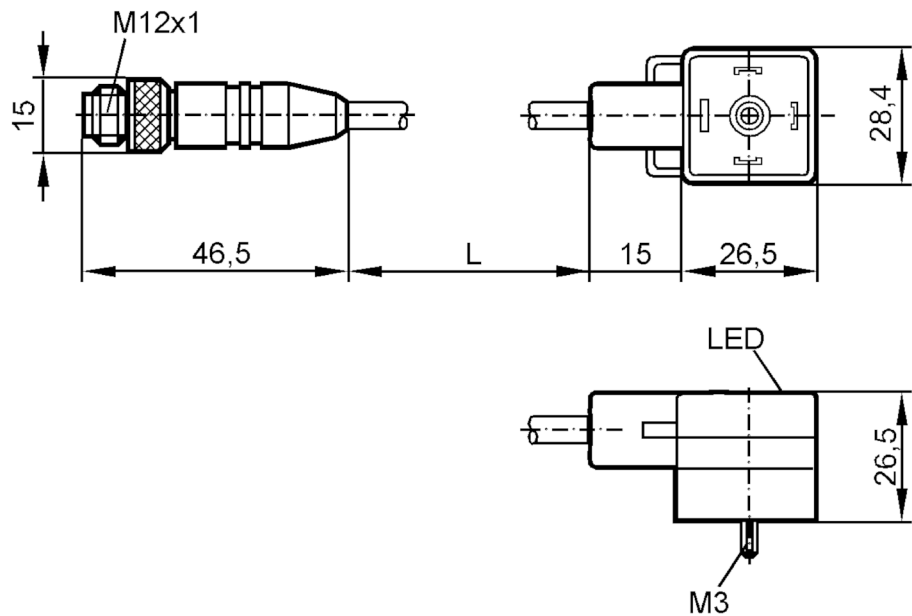

Electrical data		
Operating voltage	[V]	< 24 AC/DC
Overvoltage protection		yes; (VDR)
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67
Mechanical data		
Dimensions	[mm]	15 x 15 x 46.5
Material		TPU (urethane)
Molded-body material		TPU (urethane)
Material nut		brass, nickel-plated
Accessories		
Items supplied		screw panel for labelling
Remarks		
Pack quantity		1 pcs.

E70215



Patchcords with valve plug

VVDAA042--S0005B05STGH050MSS

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated



Electrical connection

Cable: 5 m, PUR; 3 x 0.5 mm²

Connection



Electrical connection - Socket

Connector: 1 x valve type A DIN, angled; Moulded body: TPU (urethane); Locking: brass, nickel-plated

