




Lower part for AS-Interface module

EMC-ROD

Article no longer available - archive entry

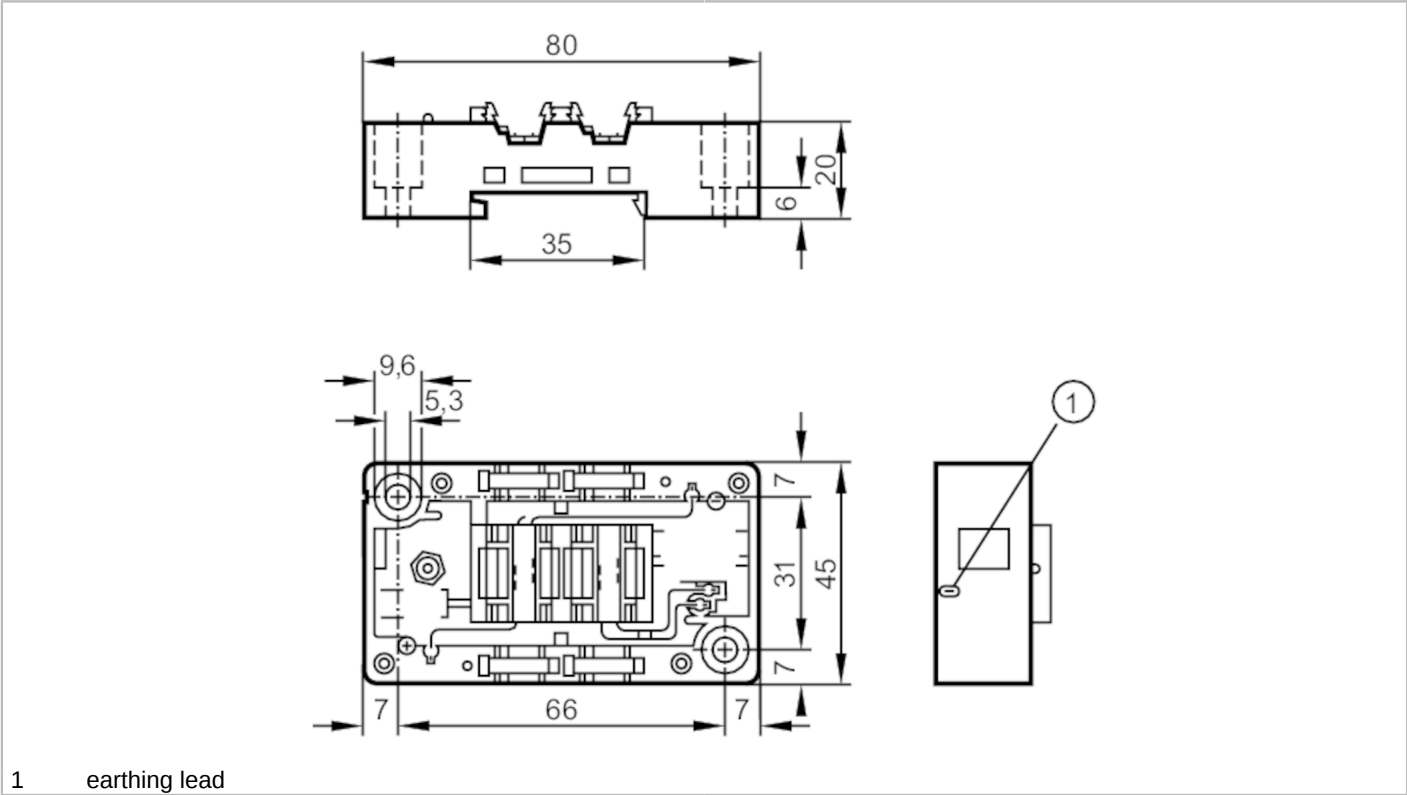

Electrical data		
Operating voltage	[V]	26.5...31.6 DC
Operating conditions		
Ambient temperature	[°C]	-25...80
Protection		IP 67; (depending on the upper part used: IP 20 / IP 65 / IP 67)
Tests / approvals		
EMC	EN 50295	
	IEC 61000-4-2	
	IEC 61000-6-2	
	IEC 61643-21	
Mechanical data		
Weight	[g]	69.5
Housing		Mounting on DIN rail and panel
Dimensions	[mm]	45 x 80 x 20
Material		PBT
Accessories		
Items supplied		connector for the ground connection
Accessories (optional)		cover:, for AS-i module, AC3000

E70371




Lower part for AS-Interface module

EMC-ROD

Remarks	
Remarks	Das EMV-Unterteil dient dem Schutz der AS-i Leitung und des Oberteils durch Ableitung hoher statischer Aufladungen oder Überspannungen. Einsetzbar nach dem Blitzschutz-zonen-Konzept an den Schnittstellen 0B -2 oder höher.
Pack quantity	1 pcs.

Electrical connection	
Connection	

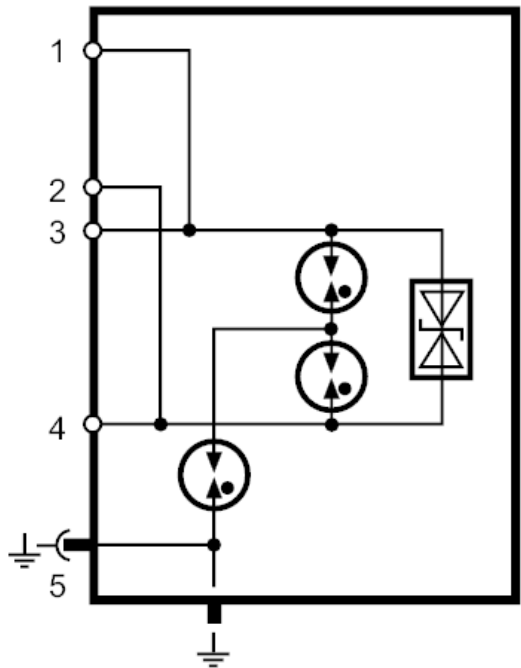

1	AS-i +
2	AS-i -
3	AS-i +
4	AS-i -
5	ground