


E73009



Wall passage


Wall passage stainless steel

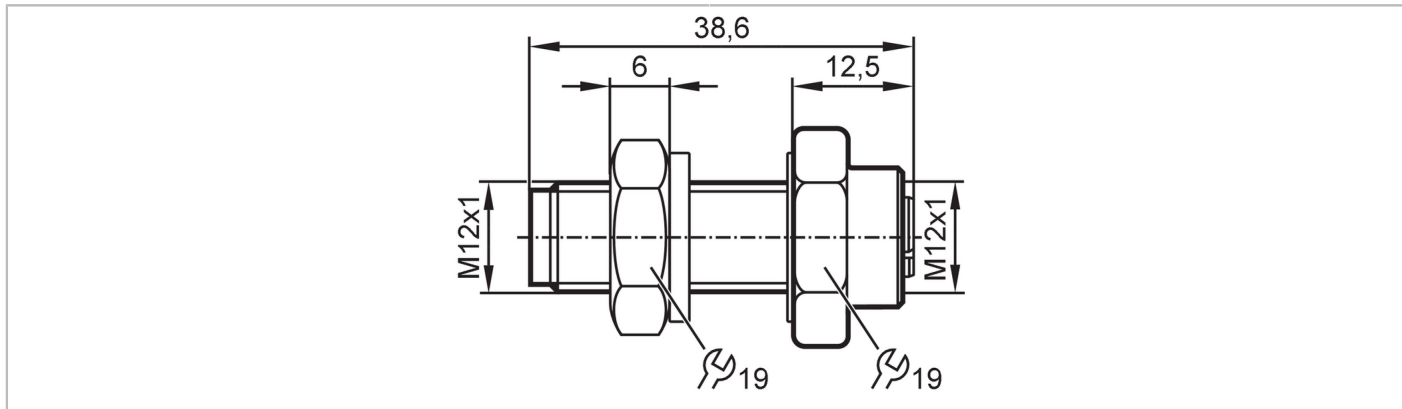

| Electrical data | |
|-----------------------------|---|
| Operating voltage [V] | < 60 AC/DC |
| Max. current load total [A] | 8; (Pin 1+3: 4 A; Pin 2+4: 4 A) |
| Operating conditions | |
| Ambient temperature [°C] | -40...85 |
| Protection | IP 65; IP 67; IP 69K |
| Mechanical data | |
| Weight [g] | 29.5 |
| Material | stainless steel (1.4305 / 303); sealing: EPDM |
| Molded-body material | stainless steel (1.4305 / 303) |
| Tightening torque [Nm] | 1 |
| Remarks | |
| Pack quantity | 1 pcs. |


Electrical connection - Socket

 Connector: 1 x M12, straight; coding: A; Contacts: 5; Moulded body: stainless steel (1.4305 / 303)



Electrical connection - plug

 Connector: 1 x M12, straight; coding: A; Contacts: 5; Moulded body: stainless steel (1.4305 / 303)



E73009



Wall passage

Wall passage stainless steel

Connection

