




AS-Interface flat cable insulation displacement
connector

FC connector PVC V2A 2m

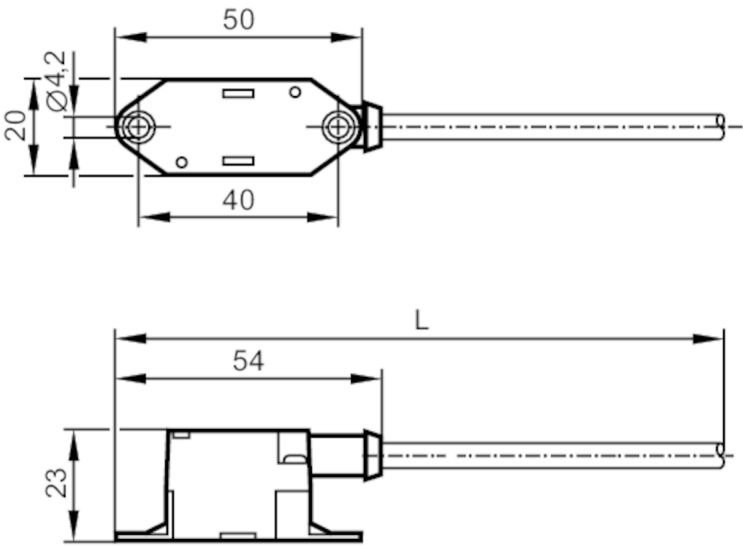

L 2140

Application		
Design		AS-i
Electrical data		
Operating voltage	[V]	26.5...31.6 DC
Max. current load total	[A]	2
Operating conditions		
Ambient temperature	[°C]	-20...70
Protection		IP 67
Mechanical data		
Weight	[g]	97.4
Material		housing Upper part: PUR; housing lower part: PA 6.6; screw: stainless steel (1.4305 / 303)
Remarks		
Remarks		The flat cable should not end in the splitter. Use a flat cable seal or heat-shrink cap for sealing.
Pack quantity		1 pcs.

E79995




AS-Interface flat cable insulation displacement connector

FC connector PVC V2A 2m

Electrical connection

Cable: 2 m, PVC, Ø 5.75 mm; 2 x 0.75 mm², PVC

Connection

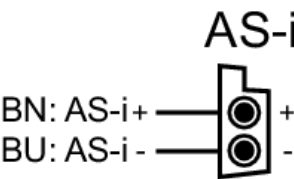

brown	AS-i +
blue	AS-i -