




Wiring block

ZDO6H050MSS0000-00STAK120MSS

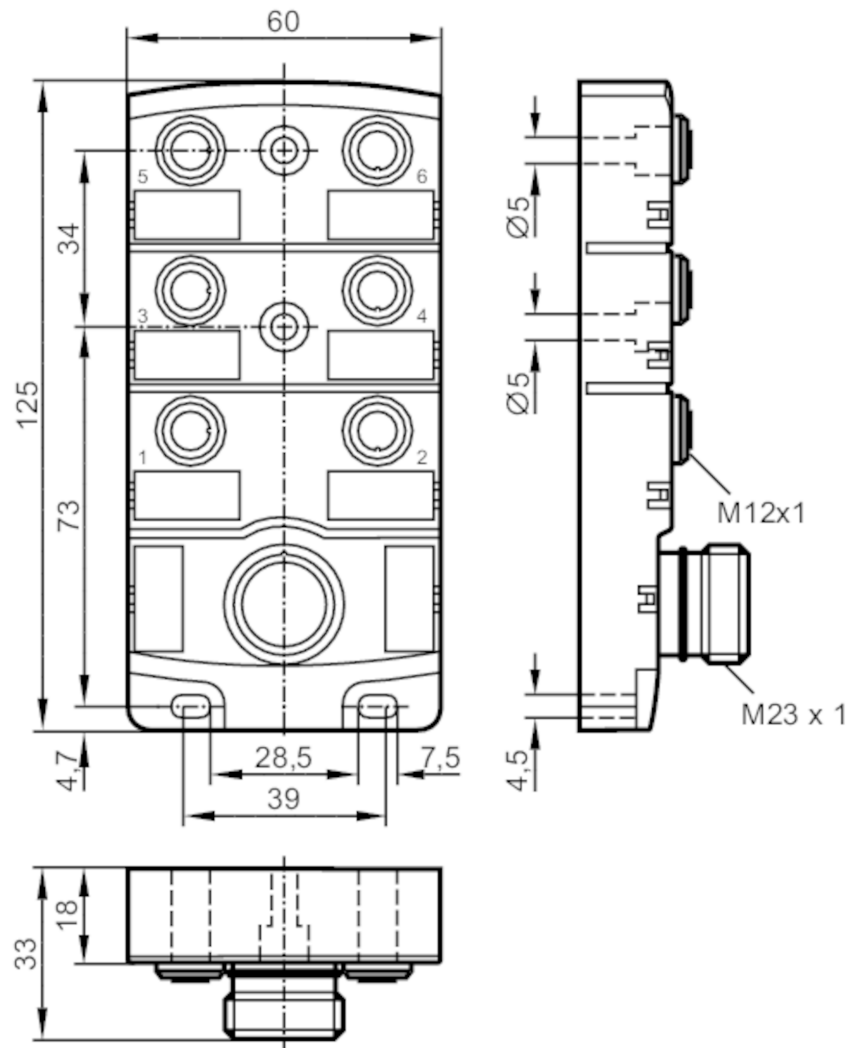

Application		
System		Free from silicone; gold-plated contacts
Free from silicone		yes
Electrical data		
Operating voltage	[V]	< 30 DC; (cULus - Class 2 source required)
Max. current load per module/slot	[A]	4
Max. current load total	[A]	12
Operating conditions		
Ambient temperature	[°C]	-25...80

EBC005



Wiring block

ZDO6H050MSS0000-00STAK120MSS


Protection	IP 67	
Tests / approvals		
UL approval	Enclosure type	Type 1
Mechanical data		
Weight	[g]	241.5
Material		PA
Molded-body material		PA
Number of ports splitter box		6
Connector type		M12
Accessories		
Items supplied	Protective caps: 2	
	labels: 6	
Remarks		
Pack quantity	1 pcs.	

Electrical connection - Connection

Connector: 1 x M23; Moulded body: PA; Contacts: gold-plated; Tightening torque: 0.8...1.5 Nm



Connection

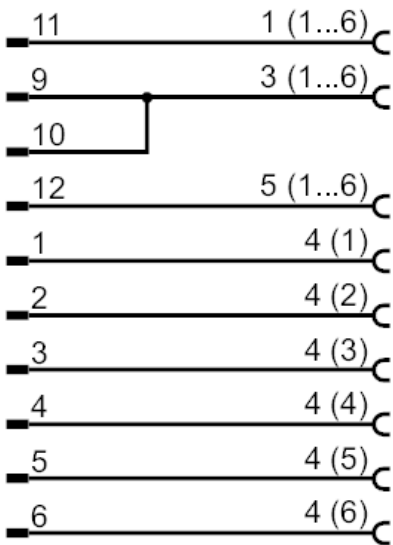

EBC005



Wiring block

ZDO6H050MSS0000-00STAK120MSS

Electrical connection - slot

Connector: 6 x M12; coding: A; Moulded body: PA; Contacts: gold-plated; Tightening torque: 0.8...1.5 Nm

