


ZDO6H050MSS0000-00STAK190MSS

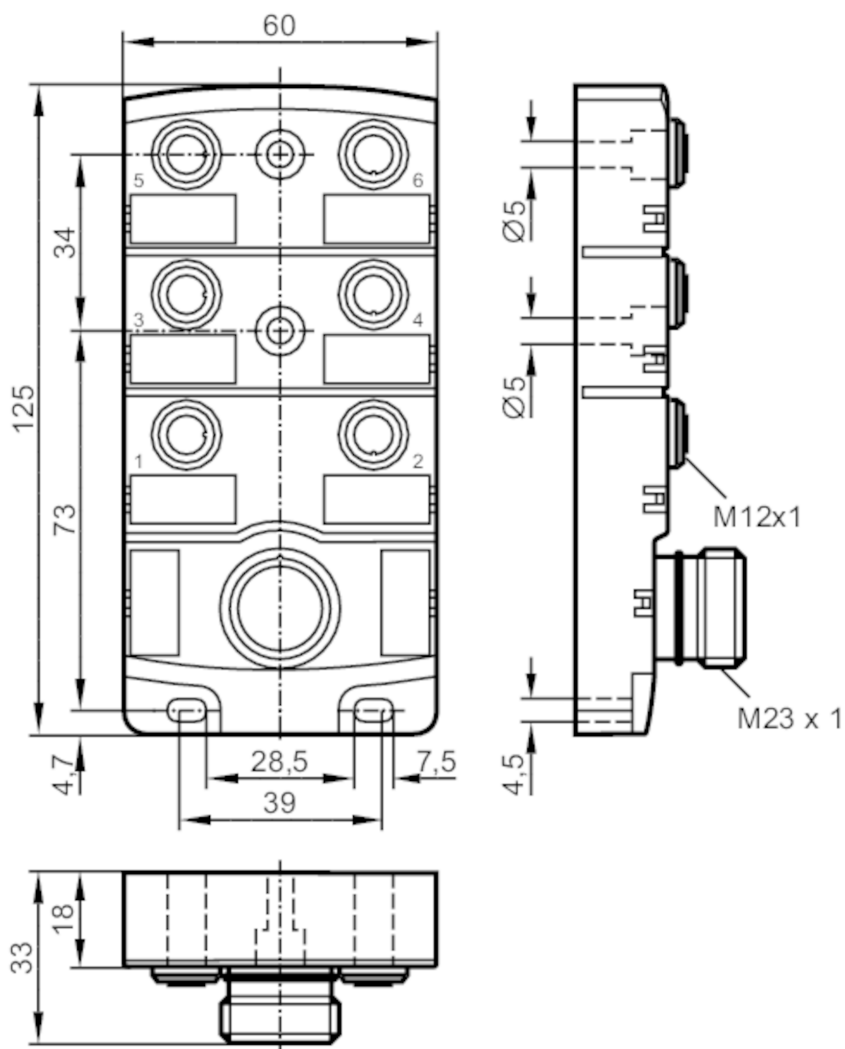

Free from silicone; gold-plated contacts

yes

< 30 DC; (cULus - Class 2 source required)

4

12

-25...80




Wiring block

ZDO6H050MSS0000-00STAK190MSS

Protection	IP 67	
Tests / approvals		
UL approval	Enclosure type	Type 1
Mechanical data		
Weight	[g]	252.5
Material		PA
Molded-body material		PA
Number of ports splitter box		6
Connector type		M12
Accessories		
Items supplied	Protective caps: 2	
	labels: 6	
Remarks		
Pack quantity	1 pcs.	

Electrical connection - Connection

Connector: 1 x M23; Moulded body: PA; Contacts: gold-plated; Tightening torque: 0.8...1.5 Nm

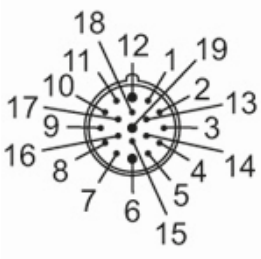

Connection

+	19	1 (1...6)	C
-	6	3 (1...6)	C
±	12	5 (1...6)	C
	15	4 (1)	C
	7	2 (1)	C
	5	4 (2)	C
	4	2 (2)	C
	16	4 (3)	C
	8	2 (3)	C
	3	4 (4)	C
	14	2 (4)	C
	17	4 (5)	C
	9	2 (5)	C
	2	4 (6)	C
	13	2 (6)	C

EBC007



Wiring block

ZDO6H050MSS0000-00STAK190MSS

Electrical connection - slot

Connector: 6 x M12; coding: A; Moulded body: PA; Contacts: gold-plated; Tightening torque: 0.8...1.5 Nm

