


EBC010



Wiring block

ZDO8H059MSS0000-00STAK120MSS

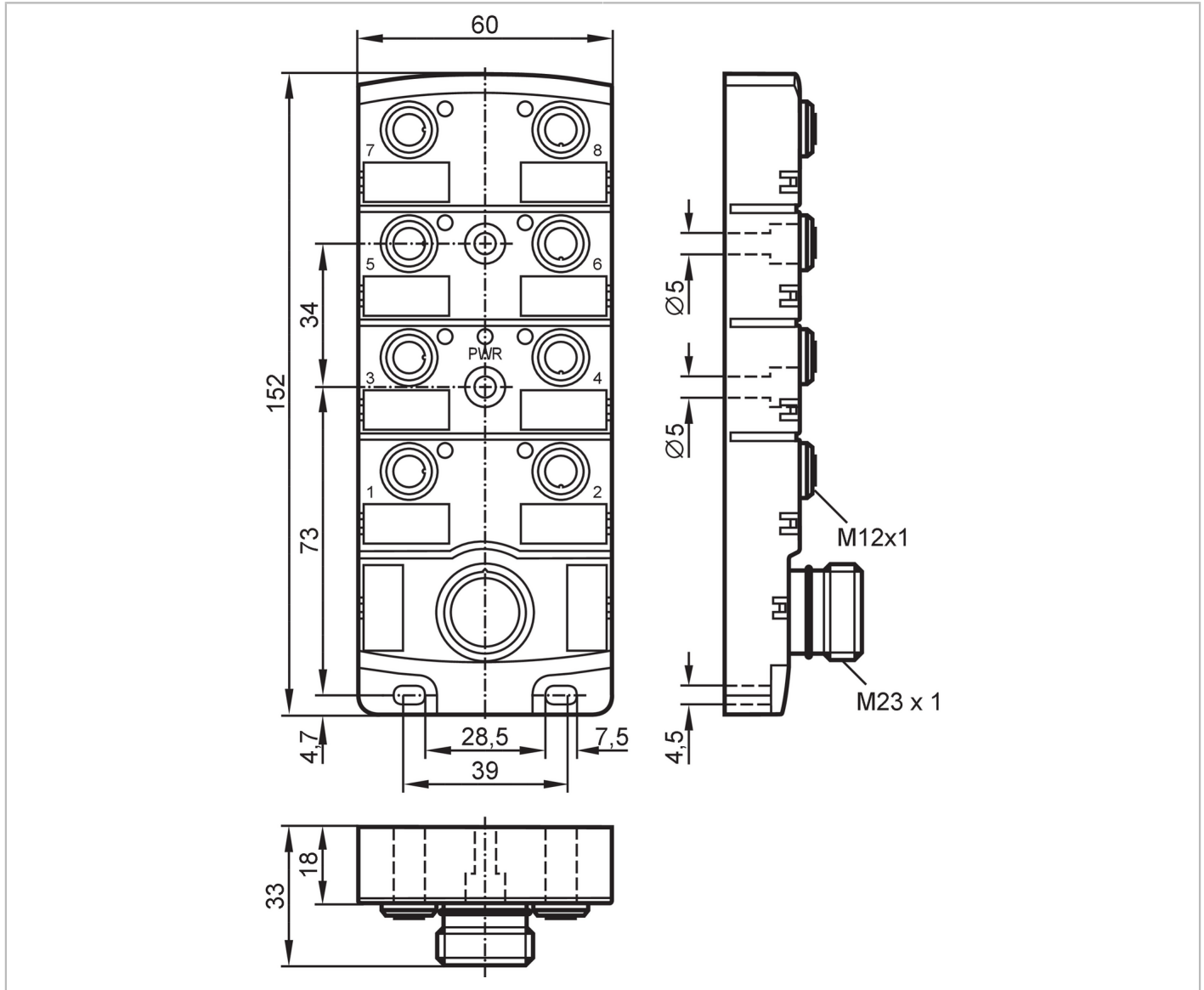


Application	
Special feature	Free from silicone; gold-plated contacts
Free from silicone	yes
Electrical data	
Operating voltage [V]	10...30 DC; (cULus - Class 2 source required)
Max. current load per module/slot [A]	4
Max. current load total [A]	12
Outputs	
Electrical design	PNP
Operating conditions	
Ambient temperature [°C]	-25...80
Protection	IP 67

EBC010



Wiring block

ZDO8H059MSS0000-00STAK120MSS

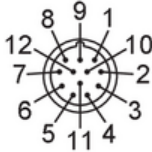
Tests / approvals		
UL approval	Enclosure type	Type 1
Mechanical data		
Weight [g]	304.5	
Housing	rectangular	
Type of mounting	Backplane mounting	
Dimensions [mm]	152 x 60 x 33	
Material	housing: PA	
Number of ports splitter box	8	
Connector type	M12	
Displays / operating elements		
Display	Switching status	8 x LED, yellow
	Power	1 x LED, green
Accessories		
Items supplied	Protective caps: 2	
	labels: 8	
Remarks		
Pack quantity	1 pcs.	
Electrical connection - Connection		
Connector: 1 x M23; Contacts: 12, gold-plated; Tightening torque: 0.8...1.5 Nm		
		



Wiring block

ZDO8H059MSS0000-00STAK120MSS

Connection

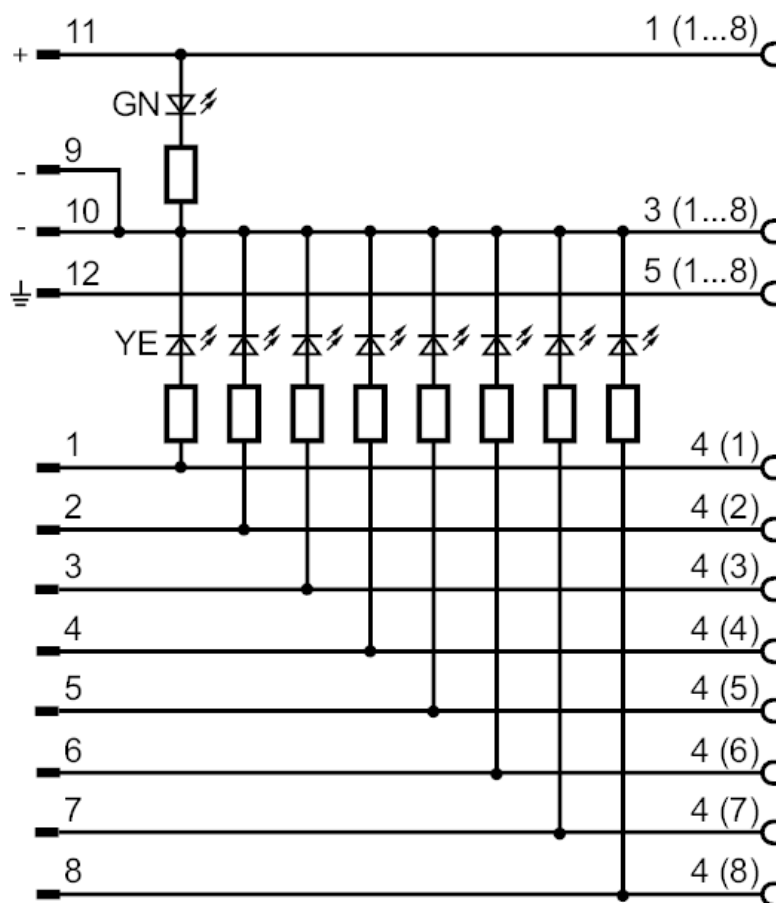

Electrical connection - slot

Connector: 8 x M12; coding: 4; Contacts: A, gold-plated; Tightening torque: 0.8...1.5 Nm

