




Wiring block

ZDO8H05HMSS0000-00STAK190MSS

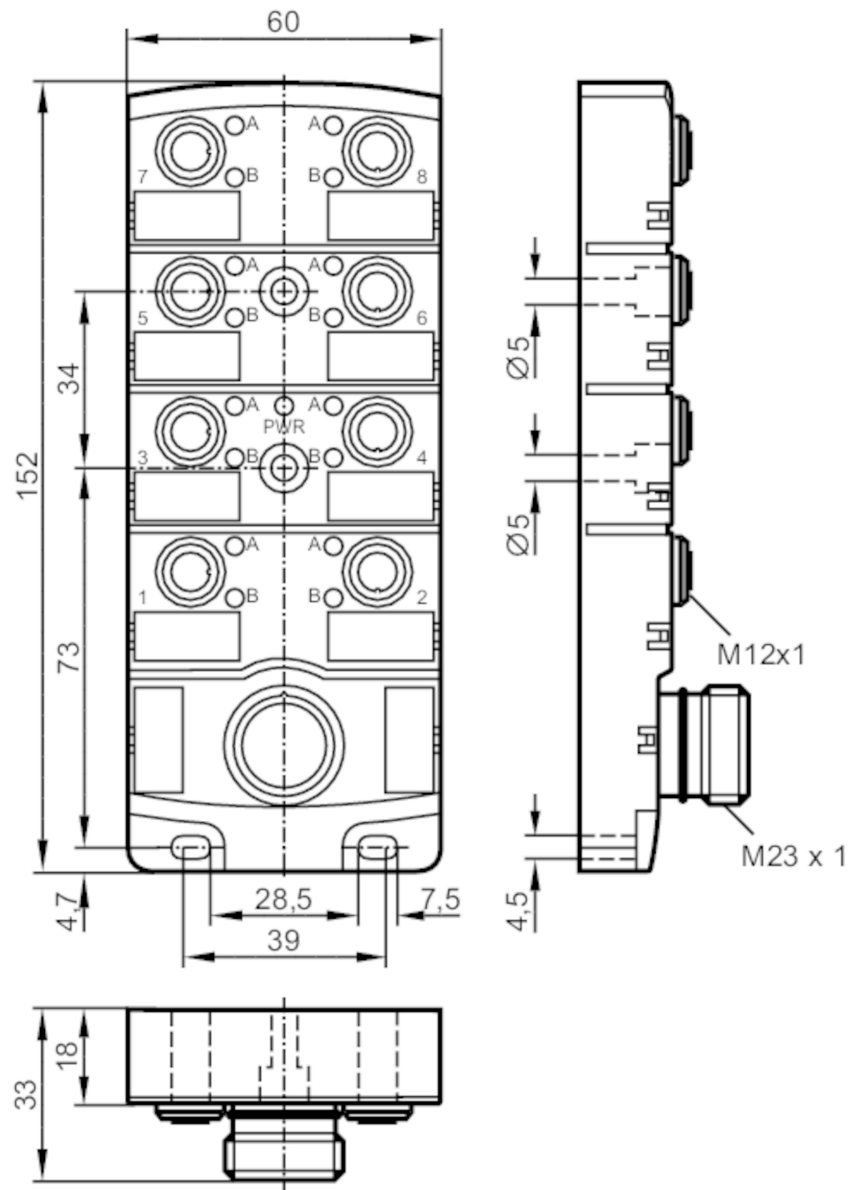


Application		
System		Free from silicone; gold-plated contacts
Free from silicone		yes
Electrical data		
Operating voltage	[V]	10...30 DC; (cULus - Class 2 source required)
Max. current load per module/slot	[A]	4
Max. current load total	[A]	10
Outputs		
Electrical design		PNP




Wiring block

ZDO8H05HMSS0000-00STAK190MSS

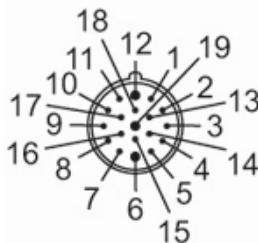Operating conditions		
Ambient temperature	[°C]	-25...80
Protection		IP 67
Tests / approvals		
UL approval	Enclosure type	Type 1
Mechanical data		
Weight	[g]	306
Dimensions	[mm]	33 x 60 x 152
Material		PA
Molded-body material		PA
Number of ports splitter box		8
Connector type		M12
Displays / operating elements		
Display	Switching status	16 x LED, yellow
	Power	1 x LED, green
Accessories		
Items supplied	Protective caps: 2	
	labels: 8	
Remarks		
Pack quantity	1 pcs.	
Electrical connection - Connection		
Connector: 1 x M23; Moulded body: PA; Contacts: gold-plated; Tightening torque: 0.8...1.5 Nm		
		

ZDO8H05HMSS0000-00STAK190MSS

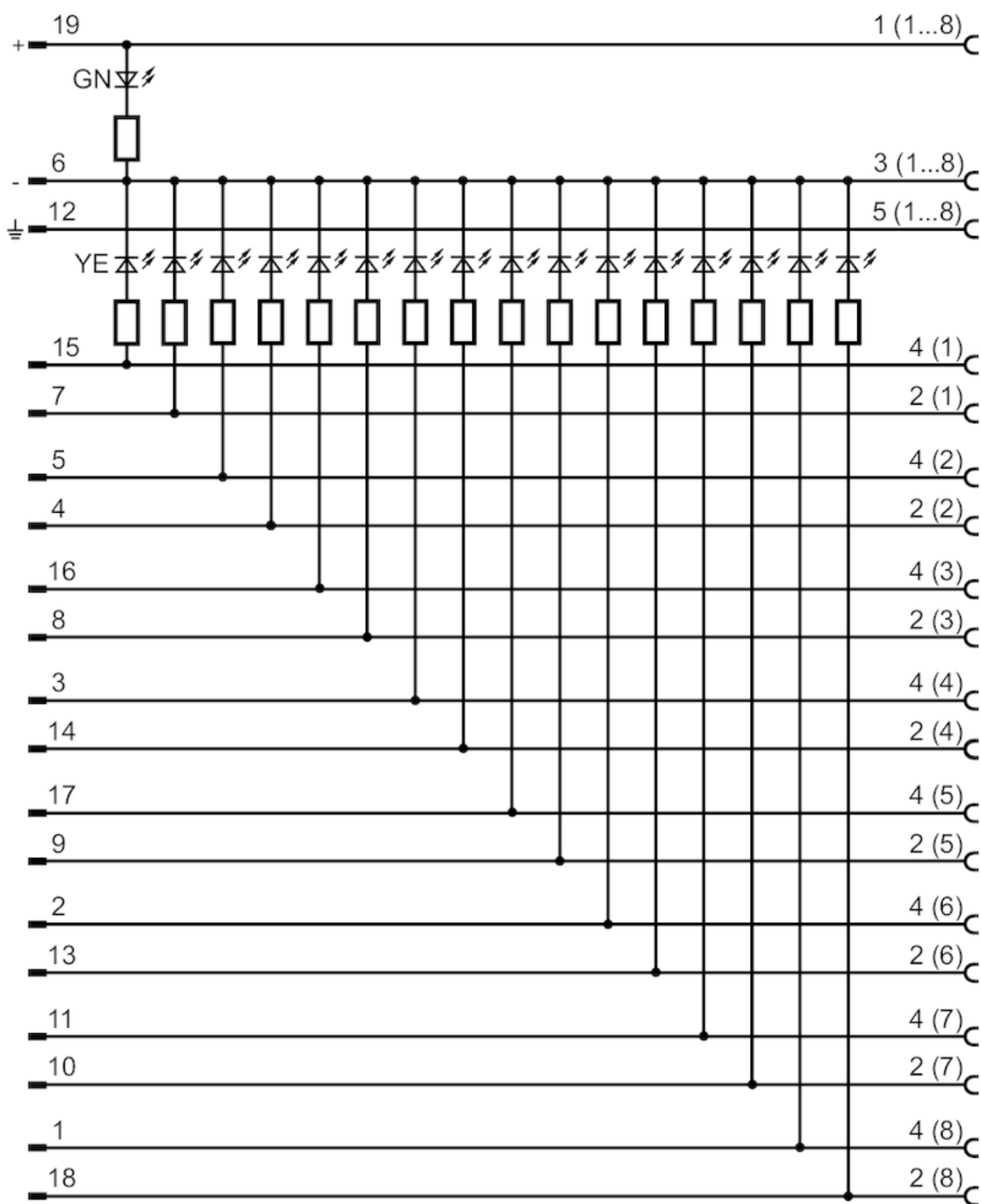

EBC012



Wiring block

ZDO8H05HMSS0000-00STAK190MSS

Electrical connection - slot

Connector: 8 x M12; coding: A; Moulded body: PA; Contacts: gold-plated; Tightening torque: 0.8...1.5 Nm

