


EBC139



Wiring block

ZDOAF03BMSS0000---STGH120MSS

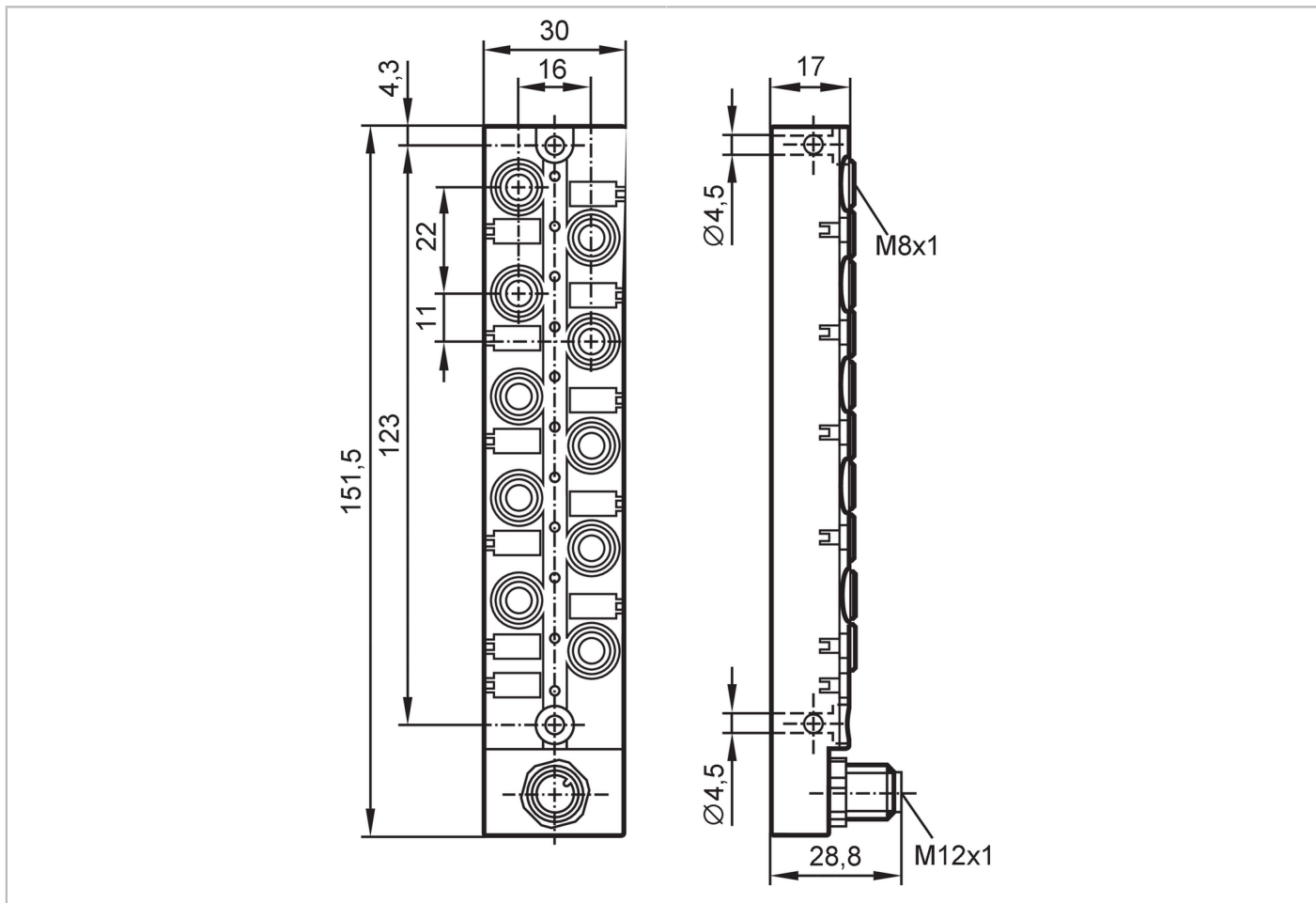

Application	
Special feature	gold-plated contacts
Application	Industrial applications; Oils and coolants
Electrical data	
Operating voltage [V]	15...30 DC; (cULus - Class 2 source required)
Protection class	III
Max. current load per module/slot [A]	2
Max. current load total [A]	2
Outputs	
Electrical design	PNP
Operating conditions	
Ambient temperature [°C]	-25...80
Ambient temperature (moving) [°C]	-5...60
Protection	IP 67; IP 68; (1 m / 7 days)
Mechanical data	
Weight [g]	150.5
Housing	rectangular

EBC139



Wiring block

ZDOAF03BMSS0000---STGH120MSS

Type of mounting	Backplane mounting
Dimensions [mm]	151.5 x 30 x 28.8
Material	housing: PBT-GF20
Material nut	brass, nickel-plated
Number of ports splitter box	10
Connector type	M8

Displays / operating elements

Display	Switching status	10 x LED, yellow
	Power	1 x LED, green

Accessories


Accessories (optional)	Protective cap: M8, E73005
------------------------	----------------------------

Remarks

Pack quantity	1 pcs.
---------------	--------


Electrical connection - Socket

 Connector: 1 x M8; coding: A; Contacts: 3, gold-plated; Locking: brass, nickel-plated; Tightening torque: 0.8...1.5 Nm



Electrical connection - plug

Connector: 1 x M12; Contacts: 12, gold-plated; Locking: brass, nickel-plated; Tightening torque: 0.8...1.5 Nm

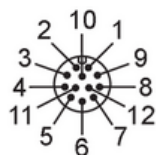

EBC139



Wiring block

ZDOAF03BMSS0000---STGH120MSS

Connection

