


EBF011



Y/T splitter

ZDO2H040VAS0000-00STGH040VAS

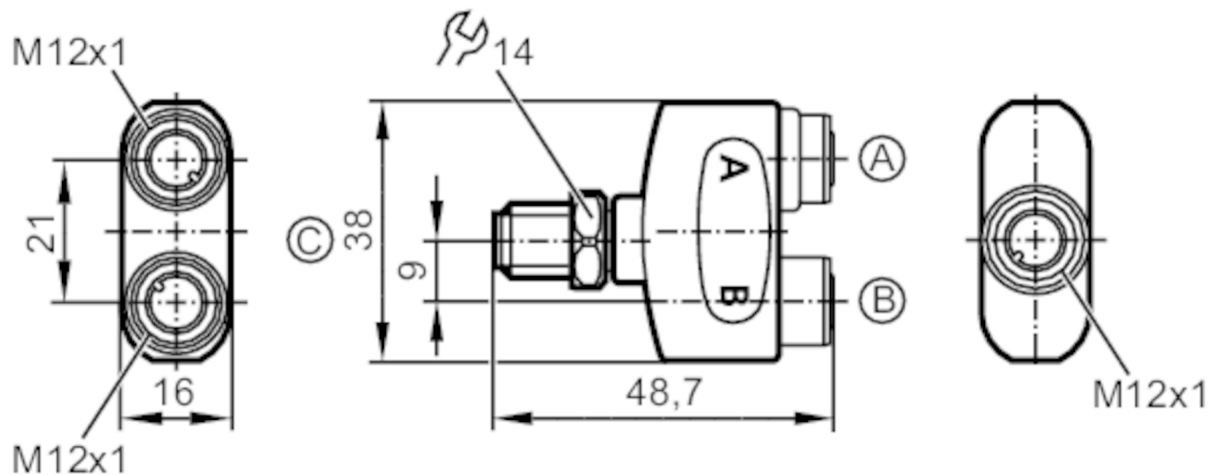

Application

System	Free from silicone; gold-plated contacts
Application	logic AND function
Free from silicone	yes

Electrical data

Operating voltage	[V]	< 60 AC/DC; (cULus: 30 AC / 42 DC)
Protection class		II
Max. current load per module/slot	[A]	4
Max. current load total	[A]	4

Operating conditions

Ambient temperature	[°C]	-25...100
Note on ambient temperature		cULus: ...65 °C
Storage temperature	[°C]	-25...55
Storage humidity	[%]	10...100
Other climatic conditions for storage according to stated class		1K22/ DIN 60721-3-1
Protection		IP 65; IP 67; IP 68; IP 69K

Tests / approvals

UL approval	voltage supply	Class 2
	File number UL	E191684

Mechanical data

Weight	[g]	33.8
--------	-----	------

EBF011



Y/T splitter

ZDO2H040VAS0000-00STGH040VAS


Material	housing: PA Halogen-free; sealing: EPDM
Molded-body material	PA, Halogen-free
Material nut	stainless steel (1.4404 / 316L)

Remarks

Pack quantity	1 pcs.
---------------	--------


Electrical connection - Socket

Connector: 2 x M12; coding: A; Moulded body: PA, Halogen-free; Locking: stainless steel (1.4404 / 316L); Contacts: gold-plated; Tightening torque: 0.6...1.5 Nm

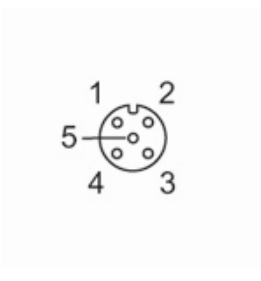

Electrical connection - plug

Connector: 1 x M12; coding: A; Moulded body: PA, Halogen-free; Locking: stainless steel (1.4404 / 316L); Contacts: gold-plated; Tightening torque: 0.6...1.2 Nm

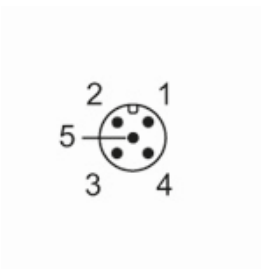

Connection

