


EBF012



Y/T splitter

ZDO2F030VAS0000-00STGH040VAS

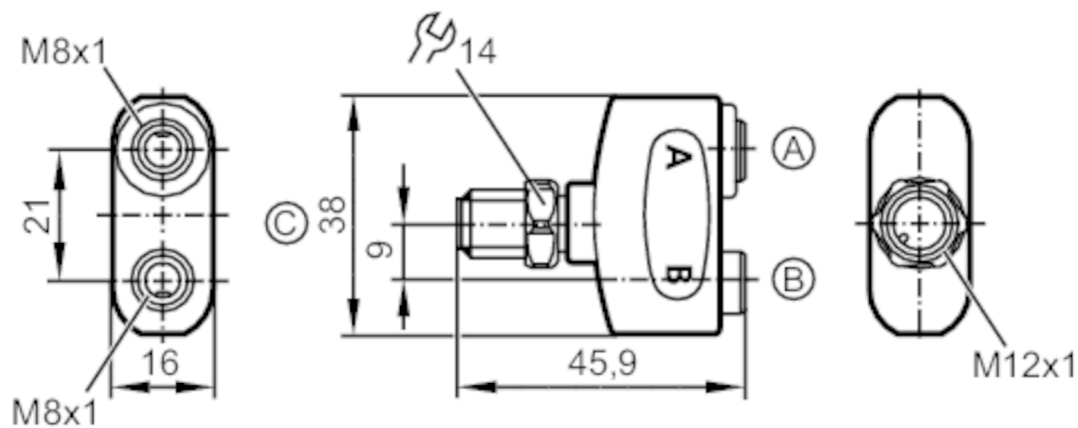

Application

System	Free from silicone; gold-plated contacts
Free from silicone	yes

Electrical data

Operating voltage [V]	< 50 AC / < 60 DC; (cULus: 30 AC / 42 DC)
Protection class	III
Max. current load total [A]	3

Operating conditions

Ambient temperature [°C]	-25...80
Note on ambient temperature	cULus: ...65 °C
Protection	IP 65; IP 67; IP 68; IP 69K

Tests / approvals

UL approval	voltage supply	Class 2
	File number UL	E191684

Mechanical data

Weight [g]	28.7
Material	housing: PA grey; Halogen-free; sealing: EPDM
Material nut	stainless steel (1.4404 / 316L)

Remarks

Pack quantity	1 pcs.
---------------	--------

EBF012



Y/T splitter

ZDO2F030VAS0000-00STGH040VAS

Electrical connection

, PUR; flame-retardant (IEC 60332-2, UL: FT2)


Electrical connection - plug

Connector: 1 x M12; coding: A; Locking: stainless steel (1.4404 / 316L); Contacts: gold-plated; Tightening torque: 0.6...1.5 Nm; Take into account the maximum value of the counterpart!



Electrical connection

Connection

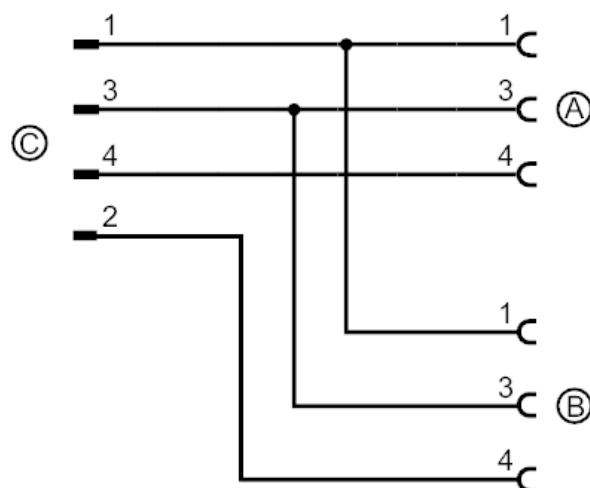

Electrical connection - Socket

Connector: 2 x M8; coding: A; Locking: stainless steel (1.4404 / 316L); Contacts: gold-plated; Tightening torque: 0.3...0.5 Nm

