


EC2025



DC-DC converter

R360/DC/DC-CONVERTER/10V

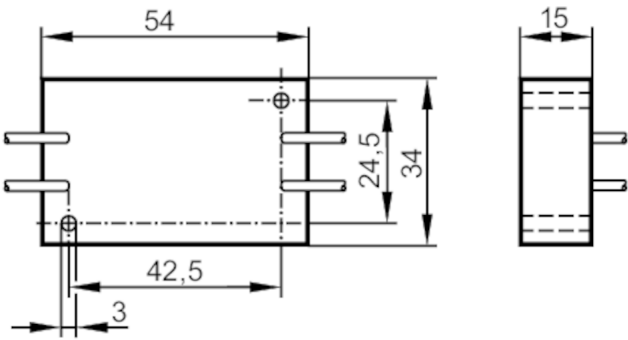

Application		
Design		housing module
Electrical data		
Operating voltage	[V]	18...36 DC
Outputs		
Output voltage	[V]	10
Short-circuit protection		yes
Overload protection		yes
Accuracy / deviations		
Accuracy		± 2 %
Operating conditions		
Ambient temperature	[°C]	-25...71
Protection		IP 67
Mechanical data		
Weight	[g]	71
Dimensions	[mm]	54 x 34 x 15
Material		housing: polyamide reinforced glass-fiber full potting
Remarks		
Pack quantity		1 pcs.
Electrical connection		
Cable: 0.28 m,; Core ends with wire end sleeves		
Input		
red	18...36 V	
black	GND	
Output		
black	10 V DC	
blue	GND	