


EC3146




Cable with connector

Cable/Connecting/14p/2m

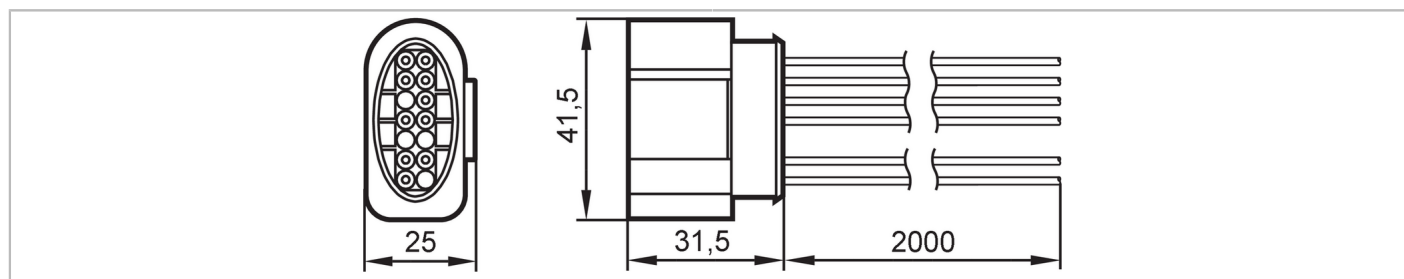

Application	
Application	Industrial applications; Use in mobile and harsh applications
Electrical data	
Operating voltage [V]	8...32 DC
Operating conditions	
Storage temperature [°C]	-40...80
Protection	IP 67
Mechanical data	
Weight [g]	147.3
Remarks	
Pack quantity	1 pcs.
Electrical connection	
Cable: 2.0 m, PUR, black; 10 x 0.5 mm ²	

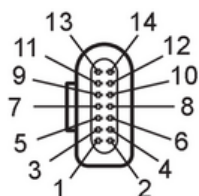


EC3146



Cable with connector

Cable/Connecting/14p/2m

Connection

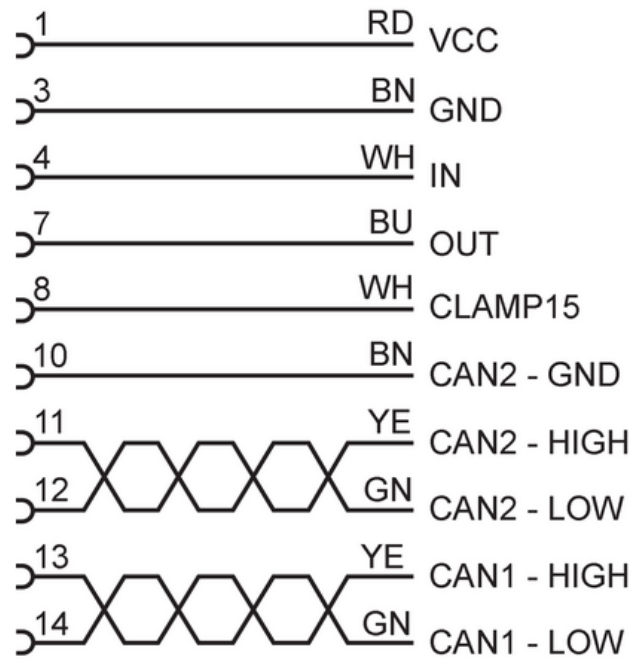

BN = brown
BU = blue
GN = green
RD = red
WH = white
YE = yellow