


EVC503



Y connection cable

YDOAHXX0MSS0,25HXXSTGH050MSS

Please see the technical note under "Downloads"

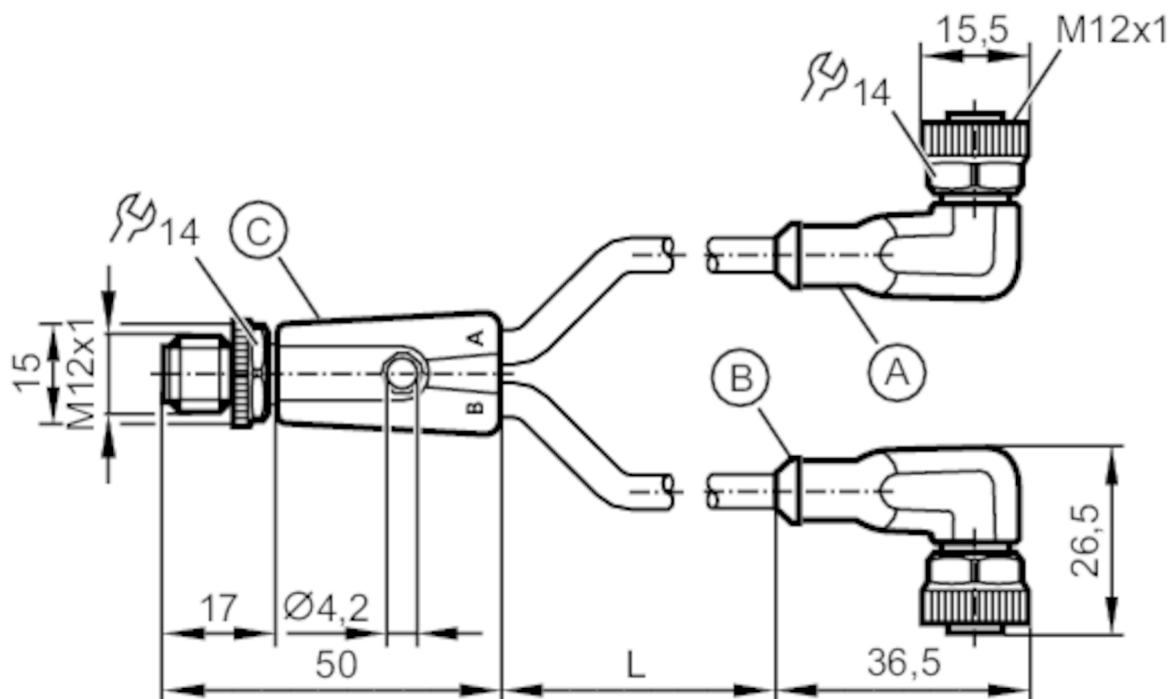

- A - input cable grey
C: octavis cable black
B -
C:



Application

System	Free from silicone; Halogen-free; gold-plated contacts; Drag chain suitability
Free from silicone	yes

Electrical data

Operating voltage [V]	10...30 DC
Protection class	II
Max. current load total [A]	3

Operating conditions

Ambient temperature [°C]	-25...90
Protection	IP 65; IP 67; IP 68; IP 69K

Mechanical data

Weight [g]	64.7
Molded-body material	TPU (urethane)
Material nut	brass, nickel-plated
Sealing material	FKM
Number of ports splitter box	2
Drag chain suitability	yes

EVC503



Y connection cable


YDOAHXX0MSS0,25HXXSTGH050MSS

Drag chain suitability	Bending radius for flexible applications	min. 10 x cable diameter
	Travel speed	max. 3.3 m/s for a horizontal travel length of 5 m and max. acceleration of 5 m/s ²
	Bending cycles	> 2 Mio.
	Torsional strain	± 180 °/m


Remarks	
Notes	Please see the technical note under "Downloads"
Pack quantity	1 pcs.

Electrical connection - plug C

Connection

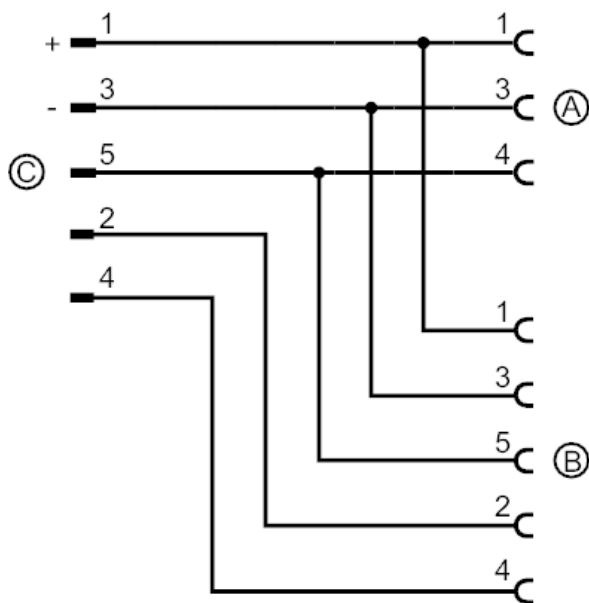

Connector: 1 x M12, straight; coding: A; Moulded body: TPU (urethane), orange; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.6...1.5 Nm

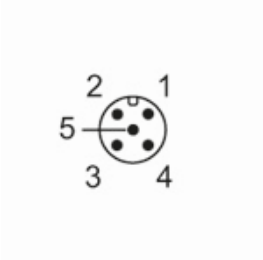



Y connection cable

YDOAHXX0MSS0,25HXXSTGH050MSS

Electrical connection - Socket A

Cable: 0.25 m, PUR, Halogen-free, grey, Ø 4.5 mm; 3 x 0.25 mm² (32 x Ø 0.1mm)

Connector: 1 x M12, angled; coding: A; Moulded body: TPU (urethane), orange; Locking: brass, nickel-plated; sealing: FKM;

Contacts: gold-plated; Tightening torque: 0.6...1.5 Nm



Electrical connection - Socket B

Cable: 0.25 m, PUR, Halogen-free, black, Ø 4.6 mm; 5 x 0.34 mm² (42 x Ø 0.1 mm)

Connector: 1 x M12, angled; coding: A; Moulded body: TPU (urethane), orange; Locking: brass, nickel-plated; sealing: FKM;

Contacts: gold-plated; Tightening torque: 0.6...1.5 Nm

