


EVF567



Wirable plug

SSTGH040VASFKPG

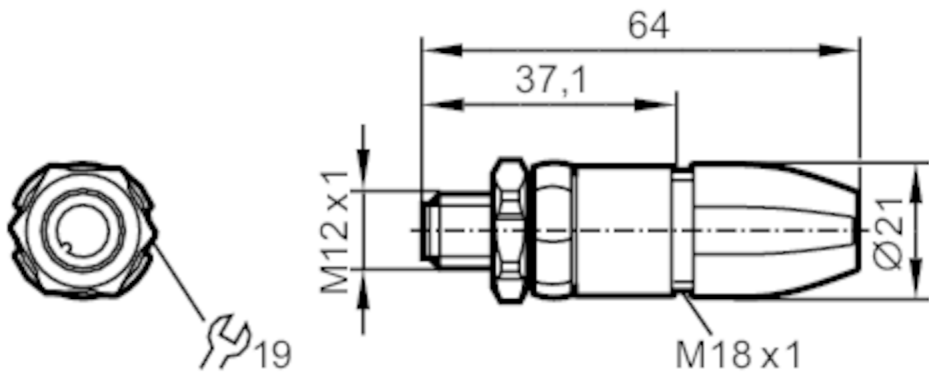

Application

System	Free from silicone; gold-plated contacts
Application	sanitary and wet areas in the food industry
Free from silicone	yes

Electrical data

Operating voltage	[V]	< 250 AC / < 300 DC
Protection class		II
Max. current load total	[A]	4; (...40 °C)

Operating conditions

Ambient temperature	[°C]	-25...100
Storage temperature	[°C]	-25...55
Storage humidity	[%]	10...100
Other climatic conditions for storage according to stated class		1K22/ DIN 60721-3-1
Protection		IP 65; IP 67; IP 68; IP 69K

Mechanical data

Weight	[g]	31.7
Molded-body material		PA 6.6
Material nut		stainless steel (1.4404 / 316L)
Sealing material		EPDM

Remarks

Pack quantity		1 pcs.
---------------	--	--------

EVF567



Wirable plug


SSTGH040VASFKPG

Electrical connection


screw terminals: 0.25...1 mm²; Cable sheath: Ø 3.5...6 mm; AWG 23...17

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: PA 6.6, grey; Locking: stainless steel (1.4404 / 316L); sealing: EPDM; Contacts: gold-plated; Tightening torque: 0.6...1.2 Nm; Take into account the maximum value of the counterpart!

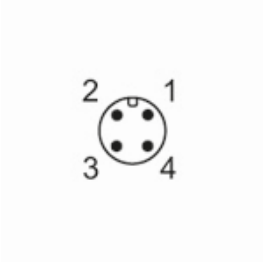

Connection

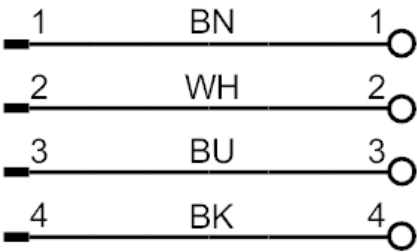

	Core colors
BK	black
BN	brown
BU	blue
WH	white
	Colors to DIN EN 60947-5-2