


# EVS003



## Female cordset

ADOGH030ZDB0010E03

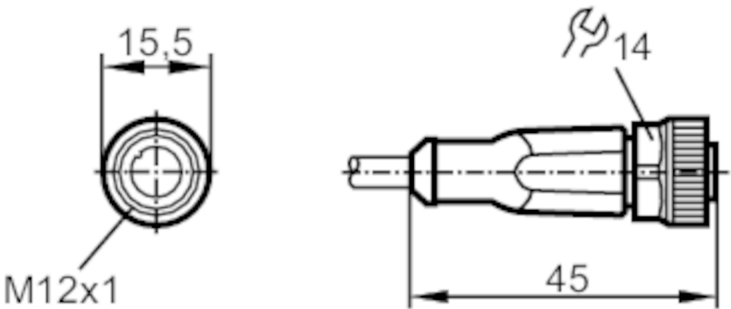

Application		
System		Free from silicone; gold-plated contacts; Drag chain suitability
Free from silicone		yes
Electrical data		
Operating voltage	[V]	< 250 AC / < 300 DC
Protection class		II
Max. current load total	[A]	4
Operating conditions		
Ambient temperature	[°C]	-25...70
Ambient temperature (moving)	[°C]	5...70
Storage temperature	[°C]	-25...55
Storage humidity	[%]	10...100
Other climatic conditions for storage according to stated class		1K22/ DIN 60721-3-1
Protection		IP 65; IP 67
Mechanical data		
Weight	[g]	321
Dimensions	[mm]	15.5 x 15.5 x 45
Material		housing: TPU (urethane) orange; sealing: FKM
Material nut		brass, nickel-plated
Drag chain suitability		yes



Female cordset

ADOGH030ZDB0010E03

Drag chain suitability	Bending radius for flexible applications	min. 10 x cable diameter
	Travel speed	max. 3.3 m/s for a horizontal travel length of 5 m and max. acceleration of 5 m/s <sup>2</sup>
	Bending cycles	1 Mio.
	Torsional strain	± 180 °/m

Remarks


Pack quantity	1 pcs.
---------------	--------

Electrical connection


Cable: 10 m, PVC, black, Ø 4.5 mm; 3 x 0.25 mm<sup>2</sup> (14 x Ø 0.15 mm )

Electrical connection - Socket

Connector: 1 x M12, straight; coding: A; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.6...1.5 Nm

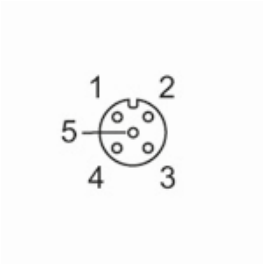

Connection

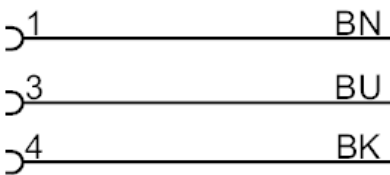

Core colors :  
BK = black  
BN = brown  
BU = blue