


EVT647



Male cordsets

ASTGF030VAS02,2E03

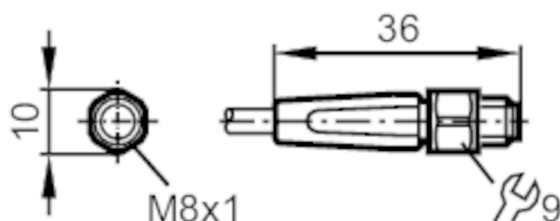

Application		
System		Free from silicone; gold-plated contacts; Drag chain suitability
Application		sanitary and wet areas in the food industry
Free from silicone		yes
Electrical data		
Operating voltage	[V]	< 50 AC / < 60 DC
Protection class		III
Max. current load total	[A]	3
Operating conditions		
Ambient temperature	[°C]	-25...80
Ambient temperature (moving)	[°C]	5...80
Storage temperature	[°C]	-25...55
Storage humidity	[%]	10...100
Other climatic conditions for storage according to stated class		1K22/ DIN 60721-3-1
Protection		IP 65; IP 67; IP 68; IP 69K
Mechanical data		
Weight	[g]	91.65
Dimensions	[mm]	10 x 10 x 36
Material		housing: PVC orange
Material nut		stainless steel (1.4404 / 316L)
Drag chain suitability		yes

EVT647



Male cordsets

ASTGF030VAS02,2E03

Drag chain suitability	Bending radius for flexible applications	min. 10 x cable diameter
	Travel speed	max. 3.3 m/s for a horizontal travel length of 5 m and max. acceleration of 5 m/s ²
	Bending cycles	> 1 Mio.
	Torsional strain	± 180 °/m

Remarks

Pack quantity 1 pcs.

Electrical connection

Cable: 2.2 m, PVC, orange, Ø 4.9 mm; 3 x 0.34 mm² (42 x Ø 0.1 mm)

Electrical connection - plug

Connector: 1 x M8, straight; coding: A; Locking: stainless steel (1.4404 / 316L); Contacts: gold-plated; Tightening torque: 0.3...0.5 Nm



Connection

1	BN
3	BU
4	BK

BK = Core colors :
BN = black
BU = brown
BK = blue