

# EVT026



## Connection cable

VDOGH030VAS0005E03STGH030VAS



### Application

|                    |                                                                  |
|--------------------|------------------------------------------------------------------|
| System             | Free from silicone; gold-plated contacts; Drag chain suitability |
| Application        | sanitary and wet areas in the food industry                      |
| Free from silicone | yes                                                              |

### Electrical data

|                         |     |                     |
|-------------------------|-----|---------------------|
| Operating voltage       | [V] | < 250 AC / < 300 DC |
| Protection class        |     | II                  |
| Max. current load total | [A] | 4                   |

### Operating conditions

|                                                                 |      |                             |
|-----------------------------------------------------------------|------|-----------------------------|
| Ambient temperature                                             | [°C] | -25...100                   |
| Note on ambient temperature                                     |      | cULus: ...50                |
| Ambient temperature (moving)                                    | [°C] | 5...100                     |
| Note on ambient temperature (moving)                            |      | cULus: ...50                |
| Storage temperature                                             | [°C] | -25...55                    |
| Storage humidity                                                | [%]  | 10...100                    |
| Other climatic conditions for storage according to stated class |      | 1K22/ DIN 60721-3-1         |
| Protection                                                      |      | IP 65; IP 67; IP 68; IP 69K |

### Mechanical data

|              |     |                                    |
|--------------|-----|------------------------------------|
| Weight       | [g] | 194.3                              |
| Material     |     | housing: PVC orange; sealing: EPDM |
| Material nut |     | stainless steel (1.4404 / 316L)    |



Connection cable

VDOGH030VAS0005E03STGH030VAS


|                        |                                          |                                                                                    |
|------------------------|------------------------------------------|------------------------------------------------------------------------------------|
| Drag chain suitability | yes                                      |                                                                                    |
| Drag chain suitability | Bending radius for flexible applications | min. 10 x cable diameter                                                           |
|                        | Travel speed                             | max. 3.3 m/s for a horizontal travel length of 5 m and max. acceleration of 5 m/s² |
|                        | Bending cycles                           | > 1 Mio.                                                                           |
|                        | Torsional strain                         | ± 180 °/m                                                                          |

Remarks

|               |        |
|---------------|--------|
| Pack quantity | 1 pcs. |
|---------------|--------|

Electrical connection - plug


Connector: 1 x M12, straight; coding: A; Locking: stainless steel (1.4404 / 316L); Contacts: gold-plated; Tightening torque: 0.6...1.5 Nm

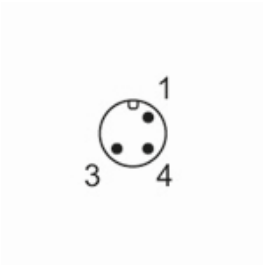

Electrical connection

Cable: 5 m, PVC, orange, Ø 4.9 mm; 3 x 0.34 mm² (42 x Ø 0.1 mm )

Connection

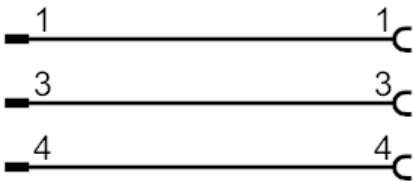

Electrical connection - Socket

Connector: 1 x M12, straight; coding: A; Locking: stainless steel (1.4404 / 316L); Contacts: gold-plated; Tightening torque: 0.6...1.5 Nm

