



## Connection cable

VDOGF030VAS01,5E03STGF030VAS



## Application

|                    |                                                                  |
|--------------------|------------------------------------------------------------------|
| System             | Free from silicone; gold-plated contacts; Drag chain suitability |
| Application        | sanitary and wet areas in the food industry                      |
| Free from silicone | yes                                                              |

## Electrical data

|                         |     |                   |
|-------------------------|-----|-------------------|
| Operating voltage       | [V] | < 50 AC / < 60 DC |
| Protection class        |     | III               |
| Max. current load total | [A] | 3                 |

## Operating conditions

|                                      |      |                             |
|--------------------------------------|------|-----------------------------|
| Ambient temperature                  | [°C] | -25...80                    |
| Note on ambient temperature          |      | cULus: ...50                |
| Ambient temperature (moving)         | [°C] | 5...80                      |
| Note on ambient temperature (moving) |      | cULus: ...50                |
| Protection                           |      | IP 65; IP 67; IP 68; IP 69K |

## Mechanical data

|                        |      |                                    |
|------------------------|------|------------------------------------|
| Weight                 | [g]  | 69.6                               |
| Dimensions             | [mm] | 10 x 10 x 36                       |
| Material               |      | housing: PVC orange; sealing: EPDM |
| Material nut           |      | stainless steel (1.4404 / 316L)    |
| Drag chain suitability |      | yes                                |



Connection cable

VDOGF030VAS01,5E03STGF030VAS


|                        |                                          |                                                                                    |
|------------------------|------------------------------------------|------------------------------------------------------------------------------------|
| Drag chain suitability | Bending radius for flexible applications | min. 10 x cable diameter                                                           |
|                        | Travel speed                             | max. 3.3 m/s for a horizontal travel length of 5 m and max. acceleration of 5 m/s² |
|                        | Bending cycles                           | > 1 Mio.                                                                           |
|                        | Torsional strain                         | ± 180 °/m                                                                          |

Remarks

|               |        |
|---------------|--------|
| Pack quantity | 1 pcs. |
|---------------|--------|

Electrical connection - plug


Connector: 1 x M8, straight; coding: A; Locking: stainless steel (1.4404 / 316L); Contacts: gold-plated; Tightening torque: 0.3...0.5 Nm

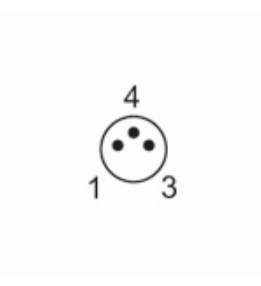

Electrical connection

Cable: 1.5 m, PVC, orange, Ø 4.9 mm; 3 x 0.34 mm² (42 x Ø 0.1 mm )

Connection

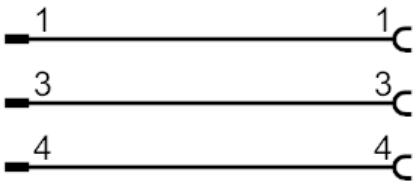

Electrical connection - Socket

Connector: 1 x M8, straight; coding: A; Locking: stainless steel (1.4404 / 316L); Contacts: gold-plated; Tightening torque: 0.3...0.5 Nm

