


EY5053



Y connection cable

Y SPLITTER CABLE HIGH RANGE

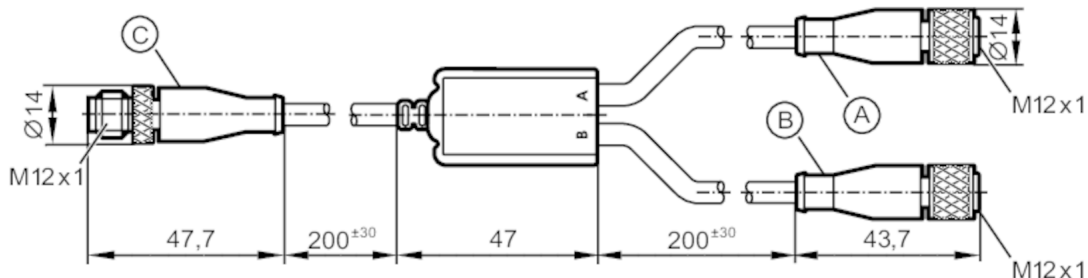

Application

System	Free from silicone; Halogen-free; gold-plated contacts; Drag chain suitability
Free from silicone	yes

Electrical data

Operating voltage	[V]	24 DC
Protection class		III
Max. current load total	[A]	3

Operating conditions

Ambient temperature	[°C]	-25...80
Protection		IP 67

Mechanical data

Weight	[g]	54.1
Molded-body material		TPU (urethane)
Material nut		brass, nickel-plated
Sealing material		FKM
Drag chain suitability		yes
Drag chain suitability	Bending radius for flexible applications	min. 15 x cable diameter
	Bending cycles	> 1 Mio.

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection - plug C

Connector: 1 x M12, straight; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.5...0.8 Nm






Y connection cable

Y SPLITTER CABLE HIGH RANGE

Electrical connection - Cable


Cable: 0.45 m, PVC, Halogen-free, black, Ø 4.2 mm; 3 x 0.25 mm²

Connection

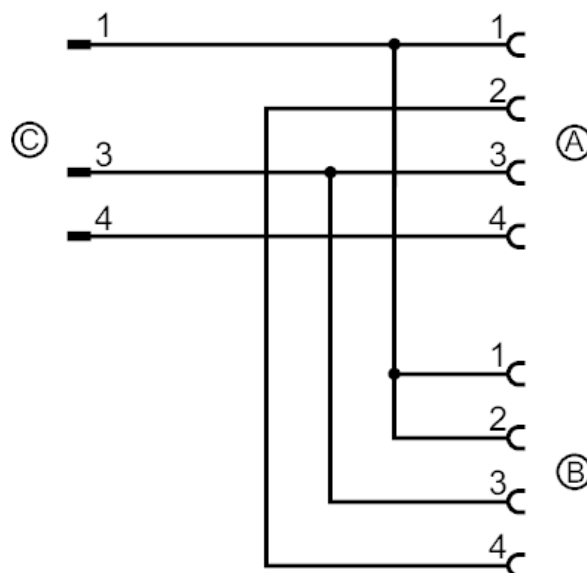

Electrical connection - Socket A

Connector: 1 x M12, straight; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated; sealing: FKM; Contacts: gold-plated; Tightening torque: 0.5...0.8 Nm

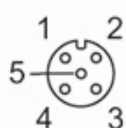

Electrical connection - Socket B

Connector: 1 x M12, straight; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated; sealing: FKM; Contacts: gold-plated; Tightening torque: 0.5...0.8 Nm

