


IF0301



Inductive sensor

IFA2004-ABOW/SL/LS-100AK

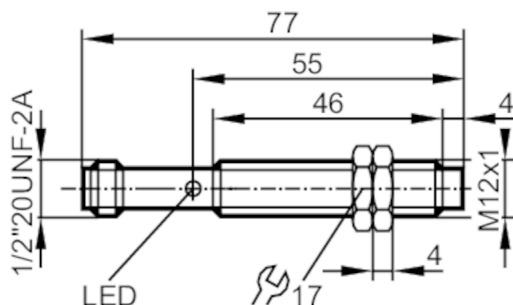

Product characteristics

Output function		normally open
Sensing range	[mm]	4
Housing		Threaded type
Dimensions	[mm]	M12 x 1 / L = 77

Electrical data

Frequency AC	[Hz]	45...65
Operating voltage	[V]	20...250 AC
Protection class		I
Reverse polarity protection		no

Outputs

Output function		normally open
Max. voltage drop switching output AC	[V]	8.5
Minimum load current	[mA]	8
Max. leakage current	[mA]	2
Permanent current rating of switching output AC	[mA]	200; (250 (...50 °C))
Short-time current rating of switching output	[mA]	900; (20 ms / 0,5 Hz)
Switching frequency AC	[Hz]	25
Short-circuit proof		no
Overload protection		no

Monitoring range

Sensing range	[mm]	4
Real sensing range Sr	[mm]	4 ± 10 %
Operating distance	[mm]	0...3.24

Accuracy / deviations

Correction factor		steel: 1 / stainless steel: 0.7 / brass: 0.4 / aluminum: 0.4 / copper: 0.3
Hysteresis	[% of Sr]	3...15
Switch-point drift	[% of Sr]	-10...10

IF0301



Inductive sensor

IFA2004-ABOW/SL/LS-100AK

Operating conditions		
Ambient temperature	[°C]	-25...80
Protection		IP 67
Tests / approvals		
EMC	EN 61000-4-2 ESD	4 kV CD / 8 kV AD
	EN 61000-4-3	3 V/m
	EN 61000-4-4 Burst	2 kV
	EN 61000-4-6	3 V
	EN 55011	class B
MTTF	[years]	932
Mechanical data		
Weight	[g]	34.6
Housing		Threaded type
Mounting		non-flush mountable
Dimensions	[mm]	M12 x 1 / L = 77
Thread designation		M12 x 1
Material		housing: brass white bronze coated; sensing face: PBT natural; Nuts: brass white bronze coated; LED window: PBT natural
Tightening torque	[Nm]	A = 3 mm: 3,5 Nm; B: 7 Nm
Displays / operating elements		
Display	Switching status	1 x LED, red
Electrical connection		
Required protection		miniature fuse to IEC60127-2 sheet 1; ≤ 2 A; fast acting
Accessories		
Items supplied		lock nuts: 2
Remarks		
Remarks		Recommendation: check the unit for reliable function after a short circuit.
Pack quantity		1 pcs.
Electrical connection - plug		
Connector: 1 x 1/2"; coding: C		
		


IF0301



Inductive sensor

IFA2004-ABOW/SL/LS-100AK

Connection

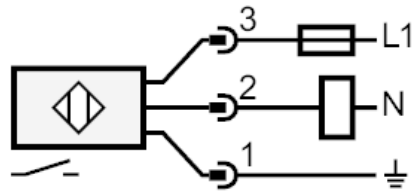

Note miniature fuse to IEC60127-2 sheet 1 ≤ 2 A fast acting

Diagrams and graphs

Installation

