


IG0400



Inductive sensor

IGA2005-ARKA

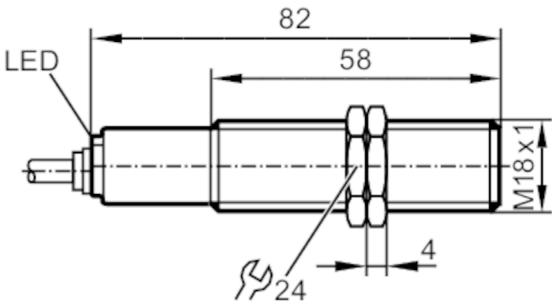

Product characteristics

Output function		normally open
Sensing range	[mm]	5
Housing		Threaded type
Dimensions	[mm]	M18 x 1 / L = 82

Electrical data

Operating voltage	[V]	75...250 AC / 20...250 DC
Protection class		II
Reverse polarity protection		yes

Outputs

Output function		normally open
Max. voltage drop switching output DC	[V]	5.5
Max. voltage drop switching output AC	[V]	5.5
Minimum load current	[mA]	4
Max. leakage current	[mA]	4
Permanent current rating of switching output AC	[mA]	100
Permanent current rating of switching output DC	[mA]	100
Short-time current rating of switching output	[mA]	900; (20 ms / 0,5 Hz)
Switching frequency AC	[Hz]	25
Switching frequency DC	[Hz]	50
Short-circuit protection		yes
Type of short-circuit protection		yes (non-latching)
Overload protection		yes

Monitoring range

Sensing range	[mm]	5
Real sensing range Sr	[mm]	5 ± 10 %
Operating distance	[mm]	0...4.05

IG0400



Inductive sensor

IGA2005-ARKA

Accuracy / deviations			
Correction factor		steel: 1 / stainless steel: 0.7 / brass: 0.5 / aluminum: 0.4 / copper: 0.3	
Hysteresis	[% of Sr]	1...15	
Switch-point drift	[% of Sr]	-10...10	
Operating conditions			
Ambient temperature		[°C]	-25...80
Protection		IP 67	
Tests / approvals			
EMC		EN 61000-4-2 ESD	4 kV CD / 8 kV AD
		EN 61000-4-3 HF radiated	3 V/m
		EN 61000-4-4 Burst	2 kV
		EN 61000-4-6 HF conducted	3 V
		EN 55011 emission	class B
MTTF	[years]	397	
UL approval		Ta	0...40 °C
		Enclosure type	Type 1
		voltage supply	Hazardous voltage
		File number UL	E174191
Mechanical data			
Weight	[g]	129	
Housing		Threaded type	
Mounting		flush mountable	
Dimensions	[mm]	M18 x 1 / L = 82	
Thread designation		M18 x 1	
Material		threaded sleeve: brass white bronze coated; sensing face: PBT; end cap: PC / TPE	
Displays / operating elements			
Display		Switching status	1 x LED, yellow
Accessories			
Items supplied		lock nuts: 2	
Remarks			
Pack quantity		1 pcs.	

IG0400




Inductive sensor

IGA2005-ARKA

Electrical connection

Cable: 2 m, PVC, Ø 4.9 mm; 2 x 0.34 mm²

Connection

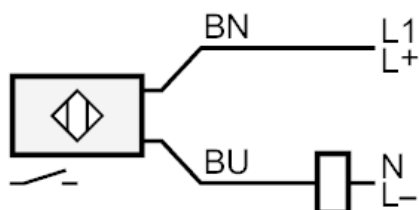

BN = Core colors :
brown
BU = blue