




Inductive sensor

IIK2015RABOA/LS-104AK

Article no longer available - archive entry

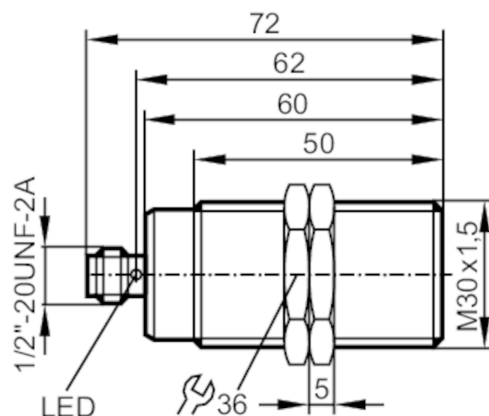

Product characteristics

Electrical design	Series connection possible: 4 pcs.	
Output function	normally open	
Sensing range [mm]	15	
Housing	Threaded type	
Dimensions [mm]	M30 x 1.5 / L = 72	

Application

System	gold-plated contacts; Increased sensing range
--------	---

Electrical data

Operating voltage [V]	20...250 AC/DC
Protection class	II
Reverse polarity protection	yes

Outputs

Electrical design	Series connection possible: 4 pcs.	
Output function	normally open	
Max. voltage drop switching output DC [V]	7.5	
Max. voltage drop switching output AC [V]	7.5	
Minimum load current [mA]	5	
Max. leakage current [mA]	4	
Permanent current rating of switching output AC [mA]	250; (350 (...50 °C))	
Permanent current rating of switching output DC [mA]	100	
Short-time current rating of switching output [mA]	2200; (20 ms / 0,5 Hz)	
Switching frequency AC [Hz]	40	

II0364



Inductive sensor

IIK2015RABOA/LS-104AK

Switching frequency DC	[Hz]	25
Short-circuit proof		no
Overload protection		no
Monitoring range		
Sensing range	[mm]	15
Operating distance	[mm]	0...12.1
Increased sensing range		yes
Accuracy / deviations		
Correction factor		steel: 1 / stainless steel: 0.7 / brass: 0.4 / aluminum: 0.3 / copper: 0.2
Hysteresis	[% of Sr]	3...15
Operating conditions		
Ambient temperature	[°C]	-25...70
Protection		IP 67
Tests / approvals		
EMC	EN 61000-4-2 ESD	4 kV CD / 8 kV AD
	EN 61000-4-3 HF radiated	10 V/m
	EN 61000-4-4 Burst	2 kV
	EN 61000-4-5 Surge	0,5 kV line to line, Ri: 2 Ohm
	EN 61000-4-6 HF conducted	10 V
	EN 55011 emission	class B
Mechanical data		
Housing		Threaded type
Mounting		flush mountable
Dimensions	[mm]	M30 x 1.5 / L = 72
Thread designation		M30 x 1.5
Material		brass white bronze coated; sensing face: PBT; lock nuts: brass
Displays / operating elements		
Display	Switching status	1 x LED, yellow
Accessories		
Items supplied		lock nuts: 2
Remarks		
Remarks	Recommendation: check the unit for reliable function after a short circuit.	
	Note	
	miniature fuse to IEC60127-2 sheet 1	
	≤ 2 A	
	fast acting	
Pack quantity		1 pcs.

II0364



Inductive sensor

IIK2015RABOA/LS-104AK

Electrical connection - plug

Connector: 1 x 1/2"; coding: C; Contacts: gold-plated

