


L32506

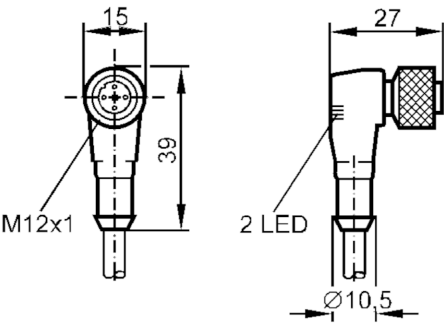

Female cordset

ADOAH042MSS0010A03



Electrical data

Operating voltage	[V]	10...30 DC
-------------------	-----	------------

Outputs

Electrical design	PNP
-------------------	-----

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 67

Mechanical data

Weight	[g]	326.586
Dimensions	[mm]	27 x 15 x 39
Material		TPU (urethane) transparent
Molded-body material		TPU (urethane), transparent
Material nut		brass, nickel-plated

Displays / operating elements

Display	Switching status	1 x LED, yellow
	Power	1 x LED, green

Remarks

Pack quantity	1 pcs.
---------------	--------

L32506



Female cordset

ADOAH042MSS0010A03

Electrical connection


Cable: 10 m, PUR / PVC, black, Ø 5 mm; 3 x 0.34 mm² (42 x Ø 0.1 mm)

Electrical connection - Socket

Connector: 1 x M12, angled; coding: A; Moulded body: TPU (urethane), transparent; Locking: brass, nickel-plated



Connection

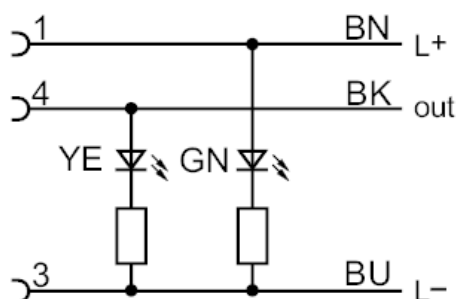

BN =	Core colors :
BK =	brown
BU =	black
	blue