


# L34010



## Y/T splitter

SPLITTER,M12 MALE,TO 2 M12 FEM

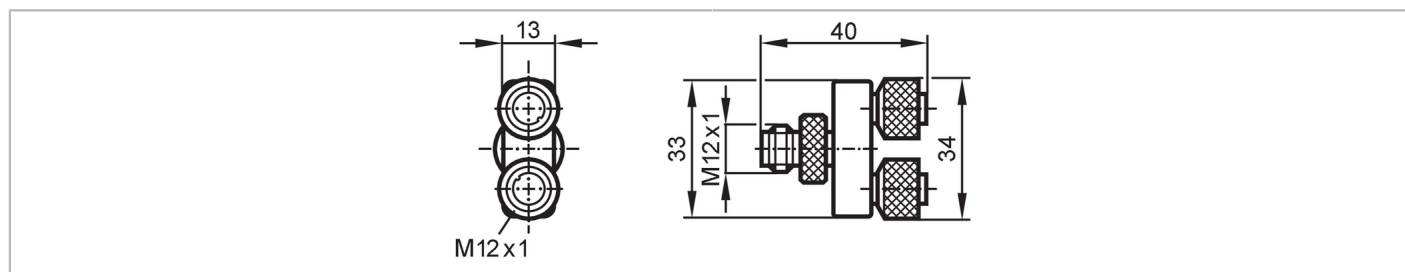

### Application

Special feature	Free from silicone; gold-plated contacts
Application	Industrial applications
Free from silicone	yes

### Electrical data

Operating voltage	[V]	< 30 AC / < 36 DC
Max. current load per module/slot	[A]	4
Max. current load total	[A]	4

### Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 67

### Mechanical data

 
Weight	[g]	22.68
Material		housing: PUR
Material nut		brass, nickel-plated / brass, PTFE coated
Number of ports splitter box		2
Connector type		M12

### Remarks

Remarks	output A nut PTFE-coated (black) output B nut nickel-plated
Pack quantity	1 pcs.

### Electrical connection - plug

Connector: 1 x M12; coding: A; Contacts: 5, gold-plated; Locking: brass, nickel-plated




# L34010



## Y/T splitter

SPLITTER,M12 MALE,TO 2 M12 FEM

### Connection

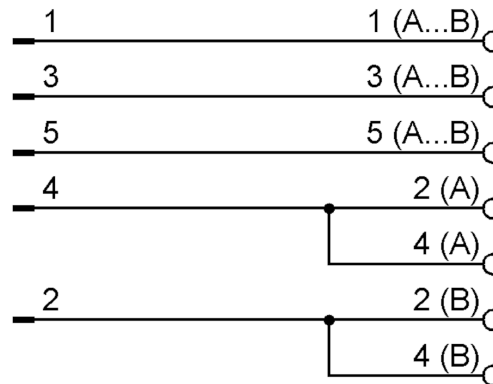

### Electrical connection - Socket

Connector: 2 x M12; coding: A; Contacts: 5, gold-plated; Locking: brass, PTFE coated

