


# L34112



## Wirable plug

SSTGB030ALSFKPG

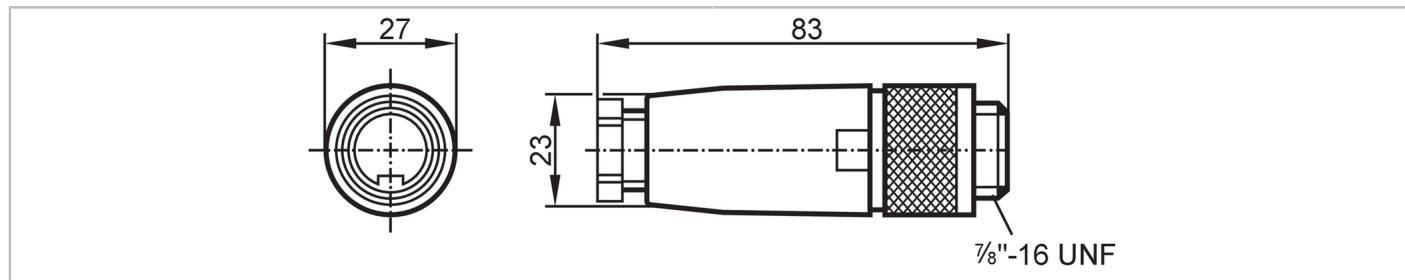

Electrical data	
Operating voltage	[V] < 600 AC
Max. current load total	[A] 12
Operating conditions	
Ambient temperature	[°C] -40...90
Protection	IP 67
Mechanical data	
Weight	[g] 45.359
Dimensions	[mm] 27 x 27 x 83
Molded-body material	PA 6.6
Material nut	aluminum, black anodized
Remarks	
Remarks	Pin 2 leading
Pack quantity	1 pcs.

**Electrical connection**  
 terminals: ...1.5 mm<sup>2</sup>; Cable sheath: Ø 6...8 mm

**Electrical connection - plug**  
 Connector: 1 x 7/8", straight; coding: A; Contacts: 3; Moulded body: PA 6.6; Locking: aluminum, black anodized

